



Southwire™

WEATHERPROOF

CATALOG


**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

SOUTHWIRE.COM

WEATHERPROOF

Southwire weatherproof products provide rugged protection to the outdoor electrical wiring. Made with aluminum die cast that covered with powder coat paint to add layer of protection and engineered plastic with UV protection. Products are designed to meet the Underwriters Laboratories standards as well as NEC® electrical code.

Metallic Boxes & Covers
Nonmetallic Boxes & Covers
Metallic & Nonmetallic While in Use Covers
Lighting and Accessories

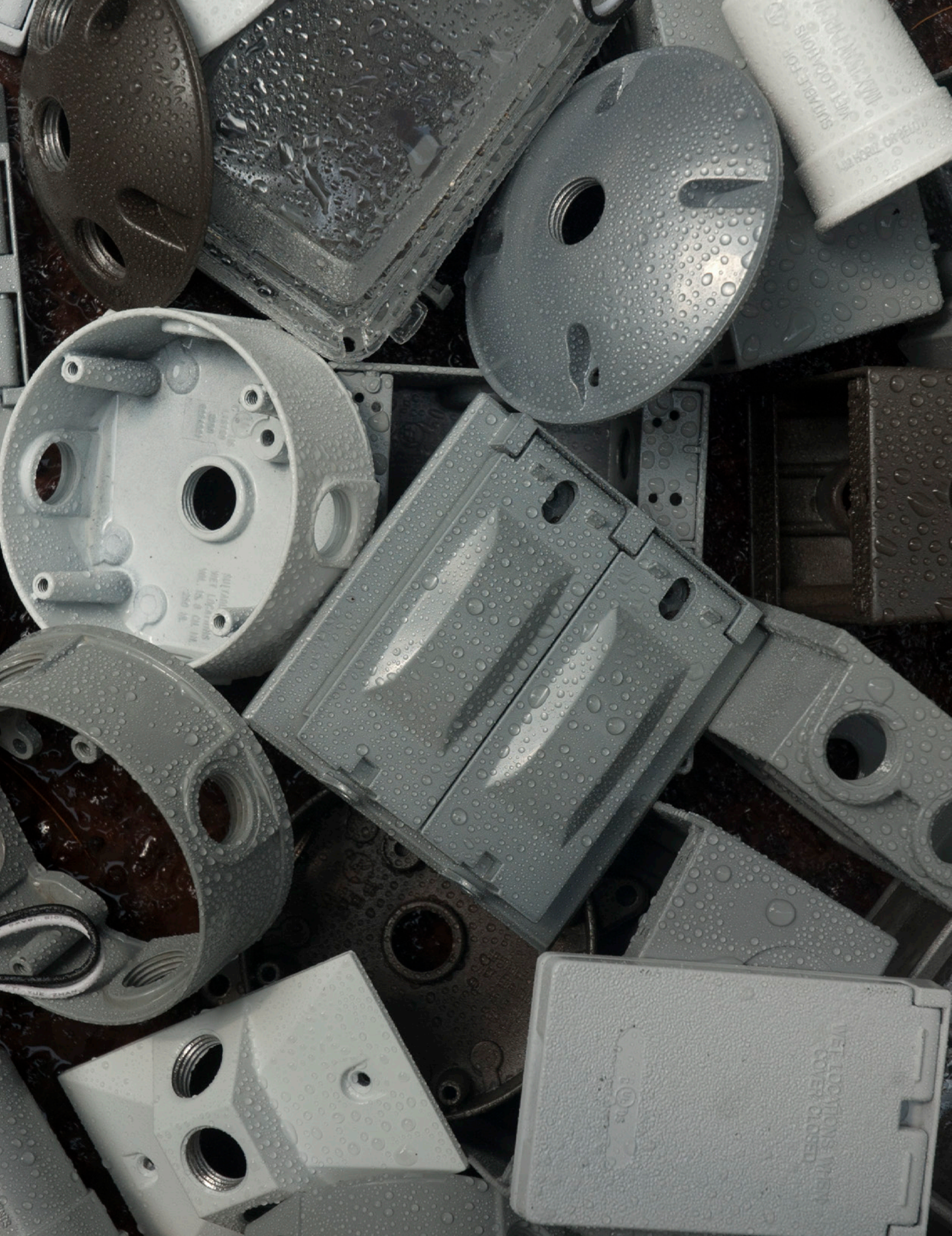

SURFACE FOR
WET LOCATIONS
COVER CLOSED

SURFACE FOR
WET LOCATIONS
COVER CLOSED

WET LOCATIONS
COVER CLOSED

DIE CAST ALUMINUM BOXES

SINGLE GANG BOXES


3 HOLE



WB1350



UL® Listed and 2011 NEC®
NEMA® 3R Compliant
NEMA FB 1

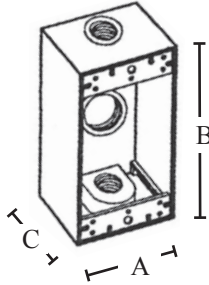

FEATURES

- 18 cubic inch capacity
- 1/2", 3/4" or 1" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include 2 closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB1350	1/2"	GRAY	25	15	2.81"	4.56"	2"
WB1350B	1/2"	BRONZE	25	15	2.81"	4.56"	2"
WB1350W	1/2"	WHITE	25	15	2.81"	4.56"	2"
WB1375	3/4"	GRAY	25	15	2.81"	4.56"	2"
WB1375B	3/4"	BRONZE	25	15	2.81"	4.56"	2"
WB1375W	3/4"	WHITE	25	15	2.81"	4.56"	2"
WB13100	1"	GRAY	25	13	2.81"	4.56"	2"


4 HOLE



WB1450



UL® Listed and 2011 NEC® and
NEMA® 3R Compliant

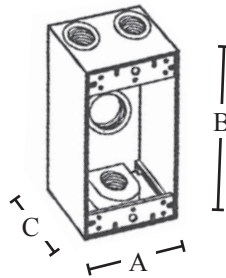

FEATURES

- 18 cubic inch capacity
- 1/2" or 3/4" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB1450	1/2"	GRAY	25	14	2.81"	4.56"	2"
WB1450B	1/2"	BRONZE	25	14	2.81"	4.56"	2"
WB1450W	1/2"	WHITE	25	14	2.81"	4.56"	2"
WB1475	3/4"	GRAY	25	14	2.81"	4.56"	2"

DIE CAST ALUMINUM BOXES

SINGLE GANG BOXES


5 HOLE



WB1550



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

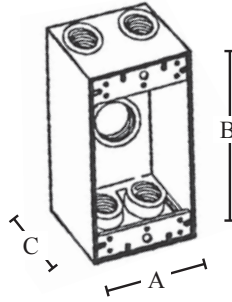

FEATURES

- 18 cubic inch capacity
- 1/2" or 3/4" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB1550	1/2"	25	13	2.81"	4.56"	2"
WB1575	3/4"	25	13	2.81"	4.56"	2"


5 HOLE SIDE OPENING



WB1550X



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

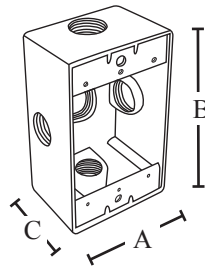

FEATURES

- 18 cubic inch capacity
- 1/2", 3/4" or 1" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish


PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB1550X	1/2"	25	13	2.81"	4.56"	2"
WB1575X	3/4"	25	13	2.81"	4.56"	2"
WB15100X	1"	25	13	2.81"	4.56"	2"

WEATHERPROOF

DIE CAST ALUMINUM BOXES

SINGLE GANG BOXES


3 HOLE DEEP

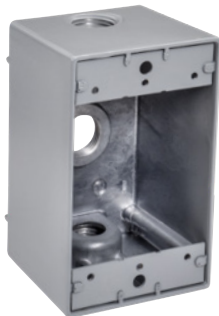

WDB1350



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

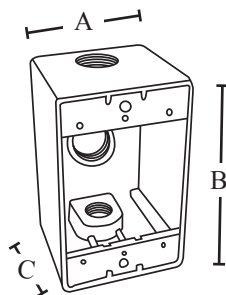

FEATURES

- 28 cubic inch capacity
- 1/2", 3/4" or 1" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL


- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WDB1350	1/2"	GRAY	20	16	2.81"	4.56"	2.62"
WDB1350B	1/2"	BRONZE	20	16	2.81"	4.56"	2.62"
WDB1350W	1/2"	WHITE	20	16	2.81"	4.56"	2.62"
WDB1375	3/4"	GRAY	20	16	2.81"	4.56"	2.62"
WDB1375B	3/4"	BRONZE	20	16	2.81"	4.56"	2.62"
WDB1375W	3/4"	WHITE	20	16	2.81"	4.56"	2.62"
WDB13100	1"	GRAY	20	16	2.81"	4.56"	2.62"


5 HOLE DEEP SIDE OPENING

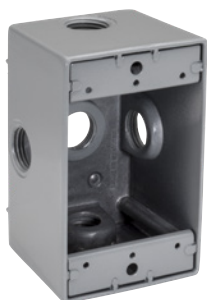

WDB1550X



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

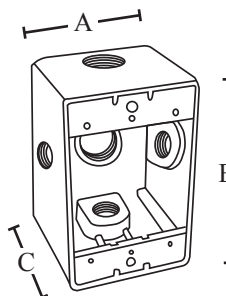

FEATURES

- 28 cubic inch capacity
- 1/2", 3/4" or 1" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WDB1550X	1/2"	20	13	2.81"	4.56"	2.62"
WDB1575X	3/4"	20	13	2.81"	4.56"	2.62"
WDB15100X	1"	20	13	2.81"	4.56"	2.62"

WEATHERPROOF


DIE CAST ALUMINUM BOXES

DOUBLE GANG BOXES

3 HOLE



WB2350

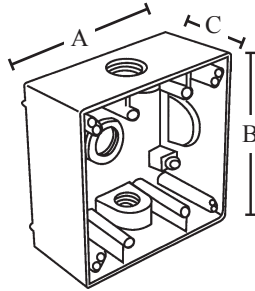

UL® Listed and 2011 NEC® and NEMA® 3R Compliant

FEATURES

- 31 cubic inch capacity
- 1/2", 3/4" or 1" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH


- Premium powder coat finish

PART #	THREADED HUB	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB2350	1/2"	GRAY	10	22	4.56"	4.56"	2"
WB2350B	1/2"	BRONZE	10	22	4.56"	4.56"	2"
WB2350W	1/2"	WHITE	10	22	4.56"	4.56"	2"
WB2375	3/4"	GRAY	10	22	4.56"	4.56"	2"
WB2375B	3/4"	BRONZE	10	22	4.56"	4.56"	2"
WB2375W	3/4"	WHITE	10	22	4.56"	4.56"	2"
WB23100	1"	GRAY	10	22	4.56"	4.56"	2"

4 HOLE



WB2450

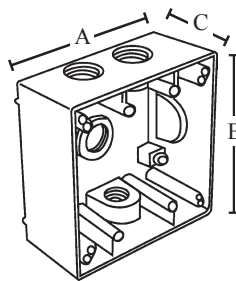

UL® Listed and 2011 NEC® and NEMA® 3R Compliant

FEATURES

- 31 cubic inch capacity
- 1/2" or 3/4" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB2450	1/2"	10	21	4.56"	4.56"	2"
WB2475	3/4"	10	21	4.56"	4.56"	2"

WEATHERPROOF

DIE CAST ALUMINUM BOXES

DOUBLE GANG BOXES


5 HOLE



WB2550



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

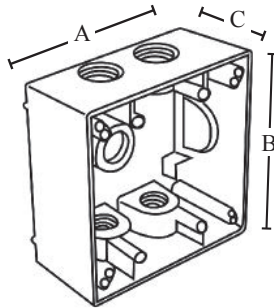

FEATURES

- 31 cubic inch capacity
- 1/2" or 3/4" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB2550	1/2"	10	20	4.56"	4.56"	2"
WB2575	3/4"	10	20	4.56"	4.56"	2"


7 HOLE



WB2750



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

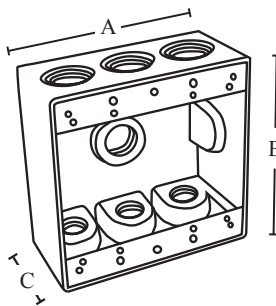

FEATURES

- 31 cubic inch capacity
- 1/2" or 3/4" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB2750	1/2"	10	20	4.56"	4.56"	2"
WB2775	3/4"	10	20	4.56"	4.56"	2"

WEATHERPROOF

DIE CAST ALUMINUM BOXES

DOUBLE GANG BOXES


5 HOLE DEEP



WDB2550



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

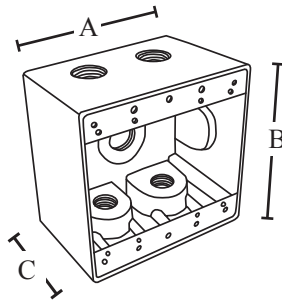

FEATURES

- 40 cubic inch capacity
- 1/2", 3/4" or 1" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WDB2550	1/2"	10	21	4.56"	4.56"	2.62"
WDB2575	3/4"	10	21	4.56"	4.56 "	2.62"
WDB25100	1"	10	21	4.56"	4.56"	2.62"


5 HOLE SIDE OPENING



WB2550X



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

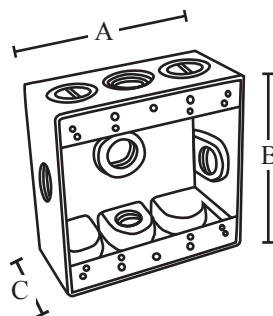

FEATURES

- 31 cubic inch capacity
- 1/2", 3/4" or 1" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB2550X	1/2"	10	20	4.56"	4.56"	2"
WB2575X	3/4"	10	20	4.56"	4.56 "	2"
WB25100X	1"	10	20	4.56"	4.56"	2"

WEATHERPROOF

DIE CAST ALUMINUM BOXES

DOUBLE GANG BOXES


6 HOLE SIDE OPENING



WB2650X



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

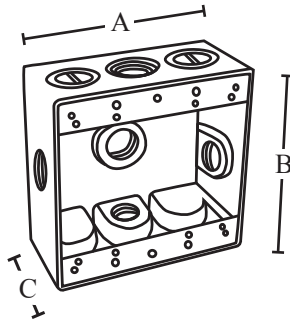

FEATURES

- 31 cubic inch capacity
- 1/2" or 3/4" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB2650X	1/2"	10	19	4.56"	4.56"	2"
WB2675X	3/4"	10	19	4.56"	4.56 "	2"


7 HOLE SIDE OPENING



WB2775X



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

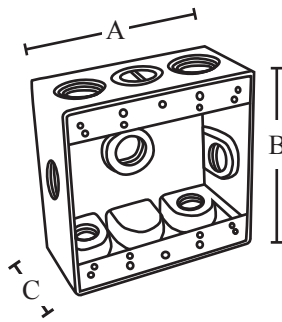

FEATURES

- 31 cubic inch capacity
- 1/2" or 3/4" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish


PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB2750X	1/2"	10	19	4.56"	4.56"	2"
WB2775X	3/4"	10	19	4.56"	4.56 "	2"

WEATHERPROOF

DIE CAST ALUMINUM BOXES

TRIPLE GANG BOXES


7 HOLE

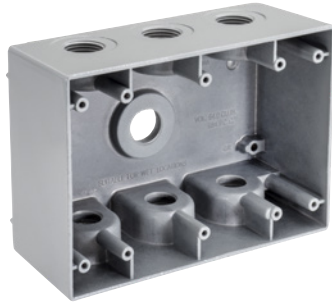

WB3750



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

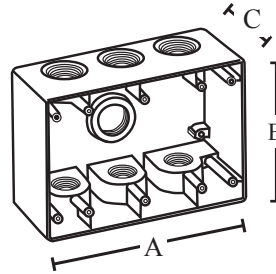

FEATURES

- 54 cubic inch capacity
- 1/2", 3/4" or 1" threaded hub
- Superior commercial quality die cast metal construction
- Boxes include closure plugs, grounding screws and mounting lugs
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For wall or pole mounting of outdoor outlets, switches or floodlights

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB3750	1/2"	5	11	6.374"	4.56"	2.625"
WB3775	3/4"	5	10	6.374"	4.56"	2.625"
WB37100	1"	5	9	6.374"	4.56"	2.625"

WEATHERPROOF


DIE-CAST ALUMINUM COVERS

SINGLE GANG COVERS

10-IN-1 VERTICAL & HORIZONTAL MULTI-USE COVER



WC1V12

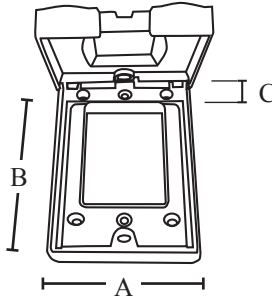

UL® Listed and 2011 NEC® and NEMA® 3R Compliant

PART #	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WC1V12	GRAY	20	22	2.81"	4.56"	.551"
WC1V12B	BRONZE	20	22	2.81"	4.56"	.551"
WC1V12W	WHITE	20	22	2.81"	4.56"	.551"

FEATURES

- Aluminum cast cover with spring loaded lid
- Can be mounted vertically or horizontally
- Heavy duty die cast metal construction
- Weather seal gasket to block moisture
- Roomy interior provides space for switches
- Lockable
- Snap in configuration enables tool free installation
- Maximum corrosion resistant fabrication
- Gray, bronze and white

APPLICATIONS

 
 
- UL listed for wet locations
- For use with single gang outdoor device box

STANDARD MATERIAL

- Precision die cast aluminum

STANDARD FINISH

- Premium powder coat finish



1 OR 3 HOLE RECTANGLE




WCR1150



WCR1350



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

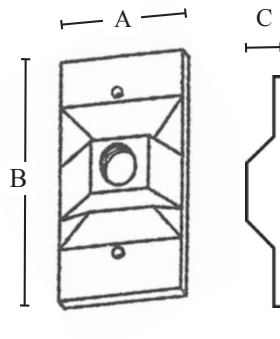

FEATURES

- 1 or 3 hole 1/2" threaded hub
- Includes gasket and screws
- Fits FS device boxes
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- Fits FS device boxes

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	# OF HOLES	COLOR	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WCR1150	1	GRAY	1/2"	50	14	2.79 "	4.55"	.99"
WCR1150W	1	WHITE	1/2"	50	14	2.79 "	4.55"	.99"
WCR1350	3	GRAY	1/2"	50	14	2.79 "	4.55"	.99"
WCR1350B	3	BRONZE	1/2"	50	14	2.79 "	4.55"	.99"
WCR1350W	3	WHITE	1/2"	50	14	2.79 "	4.55"	.99"

WEATHERPROOF

DIE-CAST ALUMINUM COVERS

SINGLE GANG COVERS


DUPLEX VERTICAL



WCV1DUP



UL® Listed and 2011 NEC® and NEMA®
3R Compliant

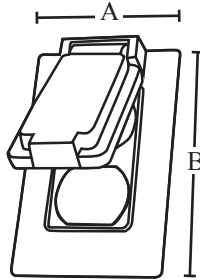

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV1DUP	50	25	2.81"	4.56"

FEATURES

- Aluminum cast cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with single gang outdoor device box

STANDARD MATERIAL

- Precision die cast zinc

STANDARD FINISH

- Premium powder coat finish


DUPLEX HORIZONTAL



WCH1DUPW



UL® Listed and 2011 NEC® and
NEMA® 3R Compliant
NEMA FB 1

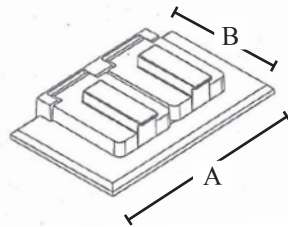

PART #	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCH1DUP	GRAY	50	35	4.56 "	2.81"
WCH1DUPB	BRONZE	50	35	4.56 "	2.81"
WCH1DUPW	WHITE	50	35	4.56 "	2.81"

FEATURES

- Heavy aluminum cast cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray, bronze or white

APPLICATIONS

- UL listed for wet locations
- Will fit all duplex receptacles in single outlet boxes

STANDARD MATERIAL

- Precision die cast aluminum

STANDARD FINISH

- Premium powder coat finish

WEATHERPROOF

DIE-CAST ALUMINUM COVERS

SINGLE GANG COVERS


RECEPTACLE SWITCH



WCV11



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

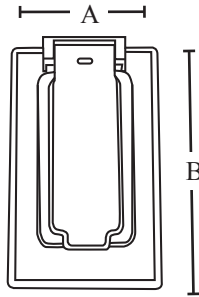

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV11	50	16	2.77"	4.52"

FEATURES

- Heavy aluminum die cast cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- Will fit 1.406" diameter receptacle in single outlet box

STANDARD MATERIAL

- Precision die cast aluminum

STANDARD FINISH

- Premium powder coat finish


HORIZONTAL GFCI



WCH1GFI



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

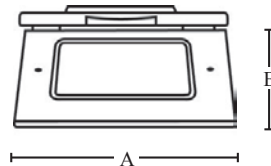

PART #	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCH1GFI	GRAY	50	20	4.56"	2.81"
WCH1GFIW	WHITE	50	20	4.56"	2.81"

FEATURES

- Heavy zinc die cast cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray and white

APPLICATIONS

- UL listed for wet locations
- For use with single gang outdoor device box

STANDARD MATERIAL

- Precision die cast zinc

STANDARD FINISH

- Premium powder coat finish

WEATHERPROOF

DIE-CAST ALUMINUM COVERS

SINGLE GANG COVERS


VERTICAL GFCI



WCV1GFI



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

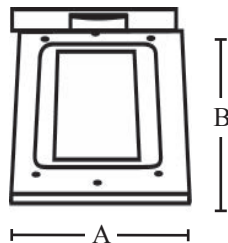

FEATURES

- Heavy zinc die cast cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray and white

APPLICATIONS

- UL listed for wet locations
- For use with single gang outdoor device box

STANDARD MATERIAL

- Precision die cast zinc

STANDARD FINISH

- Premium powder coat finish

PART #	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV1GFI	GRAY	50	20	2.81"	4.56"
WCV1GFW	WHITE	50	20	2.81"	4.56"


VERTICAL TOGGLE SWITCH HEAVY DUTY COVER



WSC1VHD



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

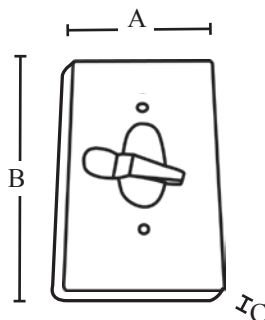

FEATURES

- Designed to fit over a toggle light switch and mounted in a weatherproof box
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with single gang outdoor device box
- NEMA 3R compliant – resistant to rain, ice, and snow

STANDARD MATERIAL

- Precision die cast aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WSC1VHD	25	7	2.81"	4.57"	.63"

WEATHERPROOF

DIE-CAST ALUMINUM COVERS

SINGLE GANG COVERS


20A/30A RECEPTACLE
30A/50A RECEPTACLE



WCV11.625



UL® Listed and 2011 NEC® and
NEMA® 3R Compliant

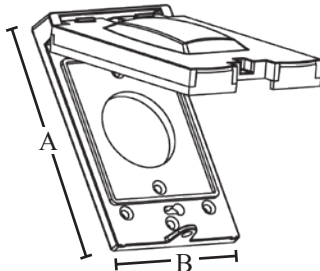

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV11.625	50	16	4.57"	2.80"
WCV12.125	50	16	4.57"	2.80"

FEATURES

- Heavy aluminum die cast cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with single gang outdoor device box

STANDARD MATERIAL

- Precision die cast aluminum

STANDARD FINISH

- Premium powder coat finish


BLANK



WC1B



UL® Listed and 2011 NEC® and
NEMA® 3R Compliant

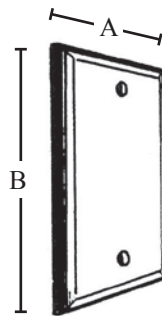

PART #	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WC1B	SILVER	100	5	2.77"	4.54"
WC1BB	BRONZE	100	5	2.77"	4.54"
WC1BW	WHITE	100	5	2.77"	4.54"

FEATURES

- Weather seal gasket to block moisture
- Installation instructions included
- Natural, bronze and white

APPLICATIONS

- UL listed for wet locations
- For use with single gang outdoor device box

STANDARD MATERIAL

- Natural - Stamped aluminum
- Bronze and White - Steel

WEATHERPROOF

DIE-CAST ALUMINUM COVERS

DOUBLE GANG COVERS


DUPLEX



WCV2DUP



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

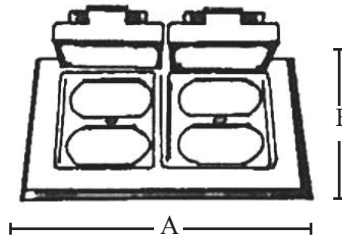

FEATURES

- Precision die cast zinc cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Precision die cast zinc

STANDARD FINISH

- Premium powder coat finish

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV2DUP	25	15	4.54"	4.54"


DUPLEX & SWITCH



WCV2SDUP



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

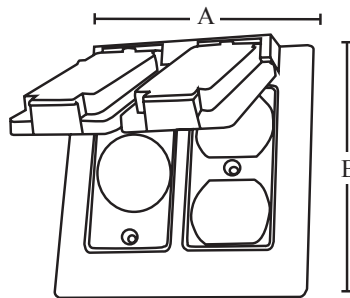

FEATURES

- Precision die cast zinc cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Precision die cast zinc

STANDARD FINISH

- Premium powder coat finish

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV2SDUP	25	16	4.54"	4.54"

WEATHERPROOF

DIE-CAST ALUMINUM COVERS

DOUBLE GANG COVERS


15 AMP SWITCH



WCV21515



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

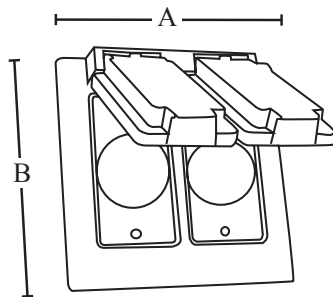

FEATURES

- Zinc cast cover with a spring loaded lid
- Opening diameter 1.406" (2)
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Precision die cast zinc

STANDARD FINISH

- Premium powder coat finish

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV21515	25	16	4.54"	4.54"


5-IN-1 COMBO COVER TOGGLE SWITCH



WC25GFI



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

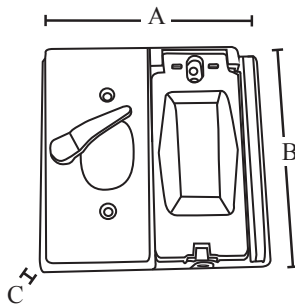

FEATURES

- Aluminum cast cover with a spring loaded lid with polycarbonate inserts
- Lockable design
- Pre-installed adhesive gasket
- Superior commercial quality die cast metal construction
- Installation instructions included
- NEMA 3R compliant
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish


PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WC25GFI	12	7	4.57"	4.63"	.63"

WEATHERPROOF

DIE-CAST ALUMINUM COVERS

DOUBLE GANG COVERS


DUPLEX-GFCI

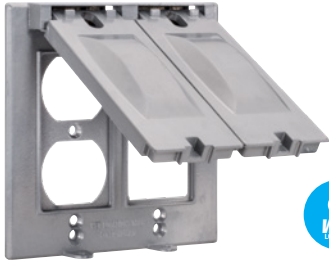

WCV2DUPGFI



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

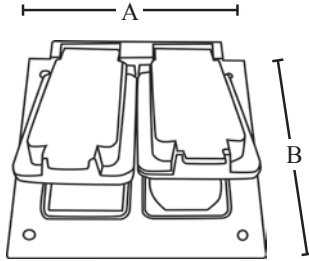

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV2DUPGFI	25	12	4.54"	4.54"

FEATURES

- Die cast zinc cover with a spring loaded lid
- Weather seal gasket to keep moisture out
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Precision die cast zinc

STANDARD FINISH

- Premium powder coat finish


VERTICAL-GFCI



WCV2GFI



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

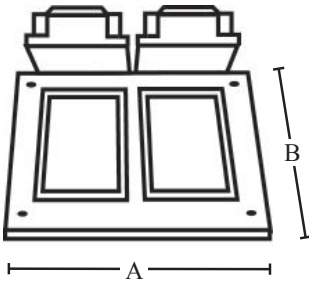

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WCV2GFI	50	35	4.54"	4.54"

FEATURES

- Precision die cast zinc cover with a spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Precision die cast zinc

STANDARD FINISH

- Premium powder coat finish

WEATHERPROOF

DIE-CAST ALUMINUM COVERS

DOUBLE GANG COVERS


TOGGLE SWITCH HEAVY DUTY



WSC22HD



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

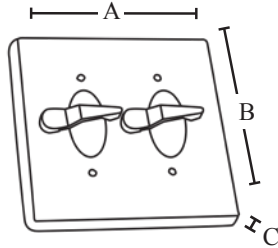

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WSC22HD	12	7	4.57"	4.63"	.63"

FEATURES

- Designed to fit over a toggle light switch and mounted in a weatherproof box
- Polycarbonate inserts
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- NEMA 3R compliant
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box
- Can be used in NEMA 3R application (resistant to rain, ice, and snow)

STANDARD MATERIAL

- Precision die cast aluminum

STANDARD FINISH

- Premium powder coat finish


20/50 AMP POWER OUTLET



WCV22125



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

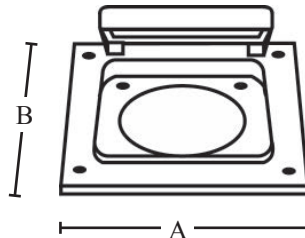

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	HOLE DIAMETER
WCV22125	8	7	4.54"	4.54"	2.125"
WCV2264	8	7	4.54"	4.54"	2.64"

FEATURES

- Aluminum cast cover with a spring loaded lid
- Weather seal gasket to block moisture
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish


DIE-CAST ALUMINUM COVERS

DOUBLE GANG COVERS

16-IN-1 VERTICAL MULTI-USE COVER



WC2225

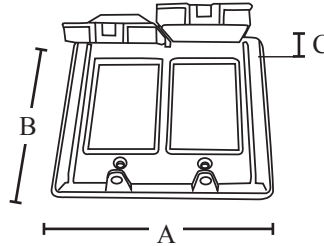

UL® Listed and 2011 NEC® and NEMA® 3R Compliant

FEATURES

- Aluminum cast multi-use cover with spring loaded lid
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- For receptacles in damp or wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Precision die cast aluminum

STANDARD FINISH


- Premium powder coat finish

PART #	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WC2225	GRAY	10	17	4.56"	4.56"	.551"
WC2225B	BRONZE	10	17	4.56"	4.56"	.551"
WC2225W	WHITE	10	17	4.56"	4.56"	.551"

BLANK



WC2B

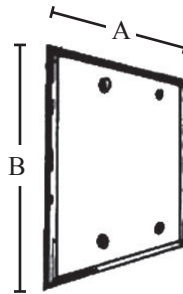

UL® Listed and 2011 NEC® and NEMA® 3R Compliant

FEATURES

- Aluminum cast cover
- Weather seal gasket to block moisture
- Installation instructions included
- Superior commercial quality die cast metal construction
- Natural, bronze and white

APPLICATIONS

- UL listed for wet locations
- For use with double gang outdoor device box

STANDARD MATERIAL

- Natural - Stamped aluminum
- Bronze and White - Steel

PART #	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WC2B	SILVER	100	11	4.62"	4.57"
WC2BB	BRONZE	100	11	4.62"	4.57"
WC2BW	WHITE	100	11	4.62"	4.57"

WEATHERPROOF


DIE-CAST ALUMINUM COVERS

TRIPLE GANG COVERS

64-IN-1 VERTICAL MULTI-USE COVER



WC3325

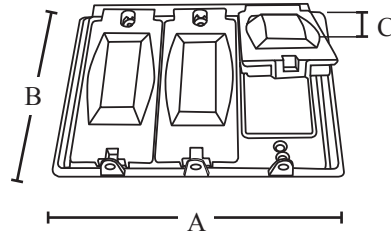

UL® Listed and 2011 NEC® and NEMA® 3R Compliant

FEATURES

- Aluminum cast multi-use cover with a spring loaded lid
- Weather seal gasket to block moisture
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with triple gang outdoor device box

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH


- Premium powder coat finish

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WC3325	5	6	6.338"	4.57"	.551"

BLANK



WC3B

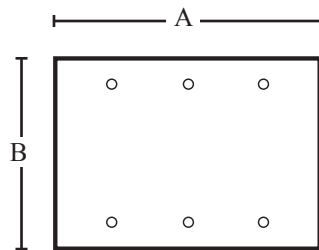

UL® Listed and 2011 NEC® and NEMA® 3R Compliant

FEATURES

- Aluminum cast cover
- Weather seal gasket to block moisture
- Superior commercial quality die cast metal construction
- Installation instructions included
- Gray

APPLICATIONS

- UL listed for wet locations
- For use with triple gang outdoor device box
- NEMA 3R compliant – resistant to rain, ice and snow

STANDARD MATERIAL

- Natural - Stamped aluminum

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WC3B	20	8	6.338"	4.57"

WEATHERPROOF

SINGLE GANG IN-USE COVERS - VERTICAL OR HORIZONTAL

14-IN-1 EXTRA DUTY IN-USE COVER



WCIU1






UL® Listed and 2011 NEC® and NEMA® 3R Compliant



PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C DEPTH
WCIU1	24	11	2.81"	4.56"	2.75"
WCIU1D	24	14	2.81"	4.56"	3.50"

  14 possible snap in configurations

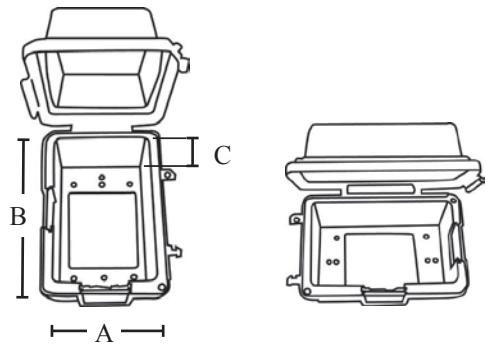

FEATURES

- Mounts vertically or horizontally
- Pre-installed adhesive gasket
- Swivel device adapter enables tool free installation
- Snap in adapters enable tool free installation
- Lockable to prevent accidental disconnects
- Meets 2014 NEC article 406.8 (B) (1)
- NEMA 3R compliant
- Gray with clear cover

APPLICATIONS

- UL listed for wet locations
- For use with duplex receptacles, GFCI, toggle, 1-3/8" & 1-5/8" round

STANDARD MATERIAL

- High impact polycarbonate

16-IN-1 EXTRA DUTY IN-USE SINGLE GANG COVER



 
WCIU1SD



NEMA 3R Rated, NEC 2014 compliant [article 406.9 (A) & (B)(1) "extra duty"] cULus-5FX8



16-1 snap in configurations



PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C DEPTH
WCIU1SD	8	22	6"	4.60"	3.10"

FEATURES


- Mounts vertically or horizontally
- Includes three inserts
- 16 Installation combinations
- Lockable
- Includes attached gasket and mounting hardware
- Adapters included for duplex and GFCI
- Fast mounting screw attachment
- Super duty hinge system
- Compatible with full size padlocks
- Patent pending extra-duty hinge system

APPLICATION

- UL listed for wet locations
- Use when an outdoor outlet requires weatherproof protection for both residential and commercial applications

STANDARD MATERIAL

- High impact polycarbonate

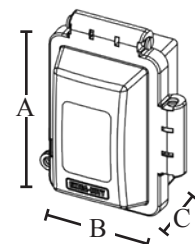

WEATHERPROOF

SINGLE GANG IN-USE COVERS

7-IN-1 METAL EXTRA DUTY IN-USE COVER



WCIU1VM



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

Meets and exceeds extra duty per 2011 NEC article 406.9.(6);
UL 514D and CSA C22.2 No. 42.1-00
NEMA 3R Rating Compliant;
UL standard 514D, cULus Listed: E254321
Fed. Spec. A-A-50563
NEMA FB 1

FEATURES

- Low profile multi height metal extra duty in-use cover
- Impact rated, withstands today's destructive forces
- Reinforced hinge withstands 40 lbs. stress test
- Lockable to prevent accidental disconnects
- Patent snap in adapters enables tool free installation
- Swing bar up or down for patent multi height position
- Expands out to 3-1/2" to gain extra clearance and accommodate internal cords
- Sleek industrial design
- Easy to open
- Extra large cord opening for heavy gauge cords

APPLICATIONS

- UL listed for wet locations
- Extra duty metal in use covers are designed for use whenever weatherproof protection is required while an outlet is in use
- Provides superior protection for industrial, commercial and residential electrical receptacles



STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	OPENING	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B	C DEPTH
WCIU1VM	2.75-3.50	10	11	4.61"	3.07"	2.39"
WCIU1HM	2.75-3.50	10	11	2.83"	4.6"1	2.39"

 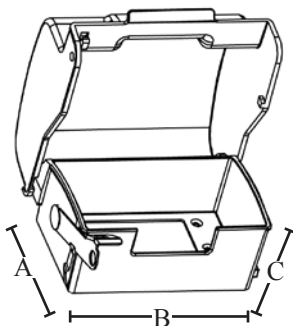

WEATHERPROOF

DOUBLE GANG IN-USE COVERS


31-IN-1 EXTRA DUTY IN USE COVER



WCIU2



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

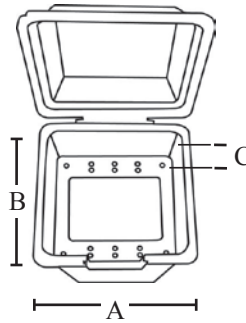

FEATURES

- Mounts vertically
- Pre-installed adhesive gasket
- Swivel device adapter enables tool free installation
- Snap in adapters enable tool free installation
- Meets 2014 NEC article 406.8 (B) (1)
- NEMA 3R compliant
- Gray with clear cover


APPLICATIONS

- UL listed for wet locations
- For use with duplex receptacles, GFCI, toggle, 1-3/8" & 1-5/8" round

STANDARD MATERIAL

- High impact polycarbonate

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C DEPTH
WCIU2	10	10	4.40"	4.54"	3.50"

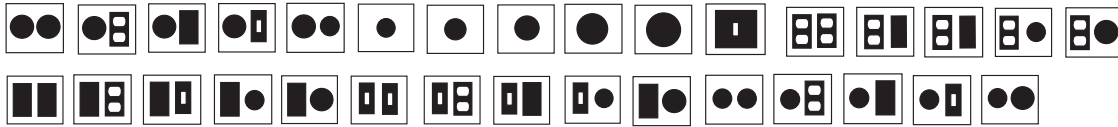


73-IN-1 EXTRA DUTY IN-USE COVER



WCIU2SD



NEMA 3R Rated, NEC 2014 compliant [article 406.9 (A) & (B)(1) "extra duty"] cULus-5FX8

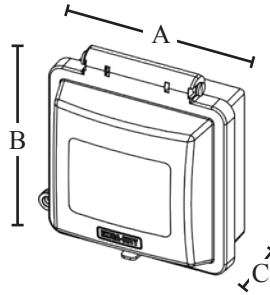

FEATURES

- Includes 7 inserts
- 73 Installation combinations
- Lockable
- Includes attached gasket and mounting hardware
- Adapters included for duplex and GFCI
- Fast mounting screw attachment
- Compatible with full size padlocks
- Patent pending extra-duty hinge system

APPLICATIONS


- UL listed for wet locations
- Use when an outdoor outlet requires weatherproof protection for both residential and commercial applications

STANDARD MATERIAL

- High impact polycarbonate

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C DEPTH
WCIU2SD	6	35	6"	6"	3.10"

Multiple combinations of Duplex, GFCI, Decorator, Blank toggle, Large toggle, 1-1/4", 1-3/8", 1-9/16", 1-5/8", 1-11/16", 2-1/8", 2-1/4", 2-7/16"

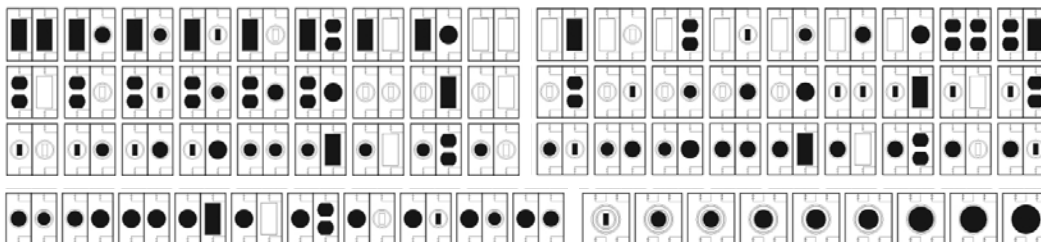

WEATHERPROOF

DOUBLE GANG IN-USE COVERS


31-IN-1 METAL EXTRA DUTY IN-USE COVER



WCIU2M



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

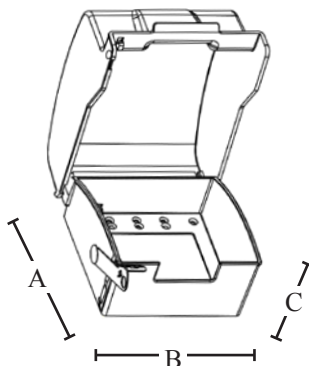

FEATURES

- Low profile multi height metal extra duty in use cover
- Impact rated, withstands today's destructive forces
- Reinforced hinge withstands 40 lbs. stress test
- Lockable to prevent accidental disconnects
- Patent snap in adapters (no tools required)
- Swing bar up or down for patent multi height position
- Expands out to 4-1/2" to gain extra clearance and accommodate internal cords
- Sleek industrial design
- Easy to open
- Extra large cord opening for heavy gauge cords

PART #	OPENING	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C DEPTH
WCIU2M	3.50-4.50	6	13	4.61"	4.61"	2.39"

APPLICATIONS


- UL listed for wet locations
- Extra duty metal in use covers are designed for use whenever weatherproof protection is required while an outlet is in use
- Provides superior protection for industrial, commercial and residential electrical receptacles

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH


- Premium powder coat finish

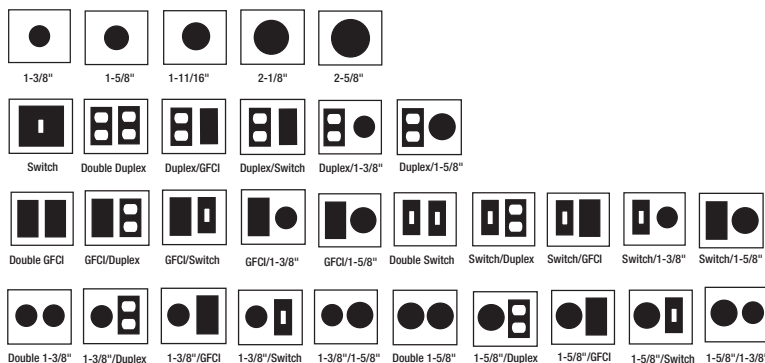

WEATHERPROOF

ROUND COVERS

1, 2, OR 3 HOLE

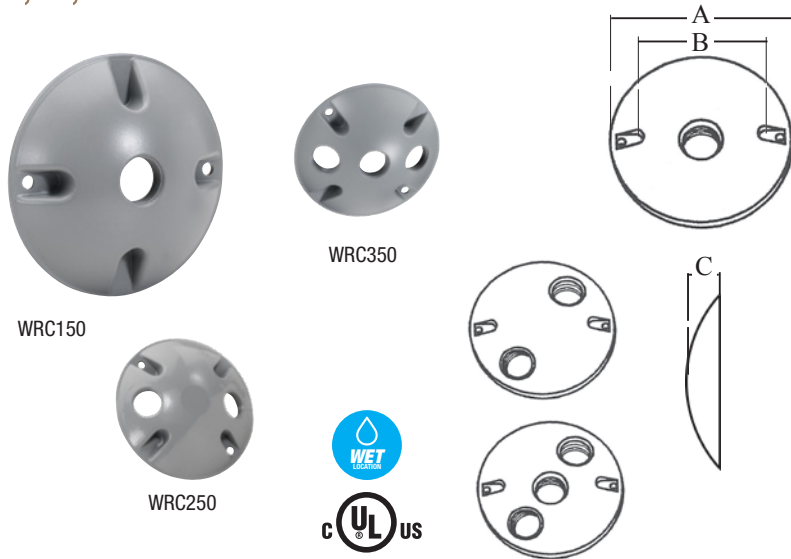

FEATURES

- NPT threads
- Weather seal gasket blocks moisture
- Installation instructions included
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- For use with round outdoor device box

STANDARD MATERIAL

- Precision die cast aluminum

STANDARD FINISH


- Premium powder coat finish

UL® Listed and 2011 NEC® and NEMA® 3R Compliant

PART #	# HOLES	THREADED HUB	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WRC150	1	1/2"	GRAY	50	9	4.50"	3.50"	8.75"
WRC150B*	1	1/2"	BRONZE	50	9	4.50"	3.50"	8.75"
WRC250	2	1/2"	GRAY	50	9	4.50"	3.50"	8.75"
WRC350	3	1/2"	GRAY	50	9	4.50"	3.50"	8.75"
WRC350B*	3	1/2"	BRONZE	50	9	4.50"	3.50"	8.75"
WRC150W**	1	1/2"	WHITE	50	9	4.50"	3.50"	8.75"
WRC250W**	2	1/2"	WHITE	50	10	4.50"	3.50"	8.75"
WRC350W**	3	1/2"	WHITE	50	10	4.50"	3.50"	8.75"

WEATHERPROOF

BLANK

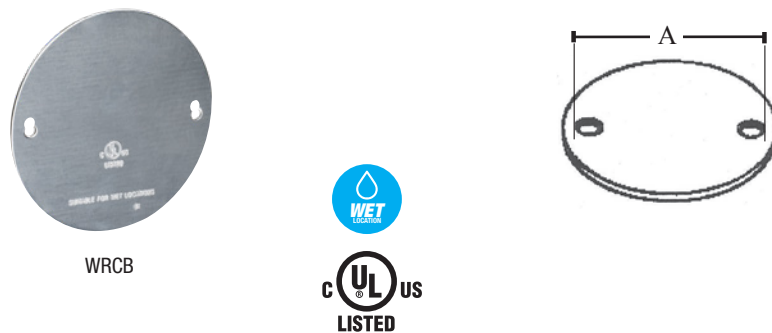

FEATURES

- Weather seal gasket and screws to keep out moisture
- Will fit round outlet boxes
- Installation instructions included
- Natural finish

APPLICATIONS

- UL listed for wet locations
- For use with round outdoor device box

STANDARD MATERIAL

- Stamped aluminum

CERTIFICATIONS

- UL Standard: UL 514A - UL514D
- Fed. Spec: W-C-586D, AA-50563
- NEMA: FB 1-2014, NEMA 3R
- 2011 NEC®

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A
WRCB	50	8	4.08"

4" ROUND BOX


5 HOLE



WRB1550W



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

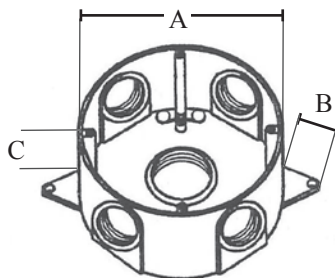

FEATURES

- 17.2 cubic inch capacity
- Includes 4 closure plugs and grounding screws
- 1/2" or 3/4" threaded hub
- For wall or ceiling mounting
- Installation instructions included
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- For use with all round outlet box and lampholder covers

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C DEPTH
WRB1550	1/2"	GRAY	25	14	4.31"	.65"	1.58"
WRB1550B	1/2"	BRONZE	25	14	4.31"	.65"	1.58"
WRB1550W	1/2"	WHITE	25	14	4.31"	.65"	1.58"
WRB1575	3/4"	GRAY	25	14	4.31"	.65"	1.58"
WRB1575W	3/4"	WHITE	25	14	4.31"	.65"	1.58"

4" ROUND EXTENSIONS


4 HOLE



WRB450EXT



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

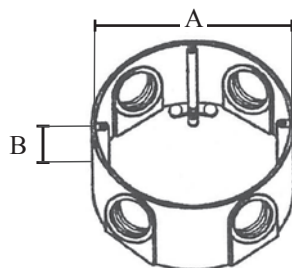

FEATURES

- Corrosion resistant die cast construction
- 1/2" or 3/4" threaded hub
- Installation instructions included

APPLICATIONS

- UL listed for wet locations
- Expands cubic capacity and enables flush finish

STANDARD MATERIAL


- Copper free aluminum

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WRB450EXT	1/2"	10	6	4.31"	1.58"
WRB475EXT	3/4"	10	6	4.31"	1.58"

SINGLE GANG EXTENSION RECTANGLE



WB1EXT

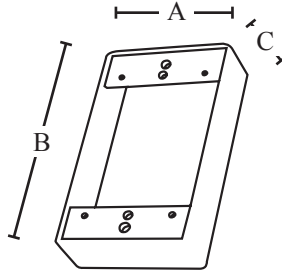

FEATURES

- Installation instructions included
- Superior commercial quality die cast metal construction

APPLICATIONS

- Expands cubic capacity and enables flush finish

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C DEPTH
WB1EXT	25	6	2.81"	4.56"	1"


4 HOLE



WB1450EXT



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

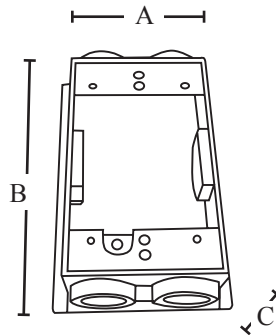

FEATURES

- 1/2" or 3/4" threaded hub
- Installation instructions included

APPLICATIONS

- UL listed for wet locations
- Expands cubic capacity and enables flush finish

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish

PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C DEPTH
WB1450EXT	1/2"	25	18	3.464"	5.236"	1.575"
WB1475EXT	3/4"	25	16	3.464"	5.236"	1.575"

WEATHERPROOF

SINGLE GANG EXTENSIONS


6 HOLE



WB1650EXT



UL® Listed and 2011 NEC® and NEMA® 3R Compliant

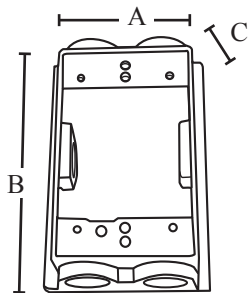

FEATURES

- NPT threads
- 1/2" or 3/4" threaded hub
- Installation instructions included

APPLICATIONS

- UL listed for wet locations
- Expands cubic capacity and enables flush finish

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish


PART #	THREADED HUB	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB1650EXT	1/2"	25	16	3.464"	5.236"	1.575"
WB1675EXT	3/4"	25	14	3.464"	5.236"	1.575"

DOUBLE GANG EXTENSION

SQUARE



WB2EXT

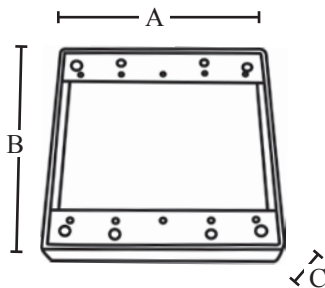

FEATURES

- Installation instructions included
- Superior commercial quality die cast metal construction

APPLICATIONS

- Expands cubic capacity and enables flush finish

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish


PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
WB2EXT	25	25	4.56"	4.56"	1"

WEATHERPROOF

PAR LAMP HOLDERS



WPAR50W

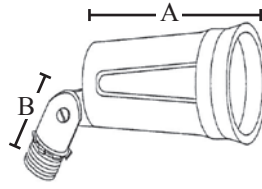

PART #	SIZE	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WPAR50	1/2"	GRAY	50	22	2.57"	2"
WPAR50B	1/2"	BRONZE	50	22	2.57"	2"
WPAR50W	1/2"	WHITE	50	22	2.57"	2"

FEATURES

- Medium base
- 1/2" locknut and gasket included
- 150 Watts max, Par38
- Swivels 180°
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations

STANDARD MATERIAL

- Copper free aluminum

STANDARD FINISH

- Premium powder coat finish


CLOSURE PLUGS



WP75



WP50PL

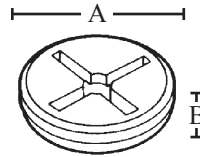

PART #	SIZE	COLOR	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
WP50	1/2"	GRAY	100	2	.79"	.33"
WP75	3/4"	GRAY	50	2	1"	.30"
WP100	1"	GRAY	25	2	1.23"	.28"
PLASTIC						
WP50PL	1/2"	GRAY	100	1	.79"	.33"
WP50PLB	1/2"	BRONZE	50	1	.79"	.33"
WP50PLW	1/2"	WHITE	50	1	.79"	.33"
WP75PL	3/4"	GRAY	50	1	1"	.30"

FEATURES

- 1/2" - 1" closure plugs
- Gray, bronze and white

APPLICATIONS

- UL listed for wet locations
- Safely seal off unused hubs in metallic outlet boxes

STANDARD MATERIAL

- Cast aluminum with powder coat finish or plastic


STANDARD FINISH

- Cast aluminum – premium powder coat finish

BOX HOLDER



WPBH150

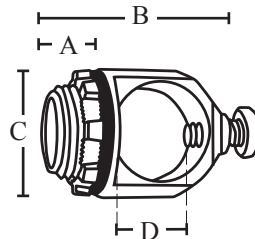

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C	D
WPBH150	1/2"	25	40	.38	1.55"	1.125"	.86"

FEATURES

- Can be used as an external means of support to meet the requirements of 2011 NEC Section 314-23
- Gray

APPLICATIONS

- Stubs up electrical boxes, and fire alarms with rigid pipe between bar joists
- Installation is easy—simply insert the box support into the electrical box. The entire assembly is held secure with a 1/2" rigid steel conduit or water pipe

STANDARD MATERIAL


- Corrosion resistant die cast zinc

RECEPTACLE COVER

SINGLE



1317

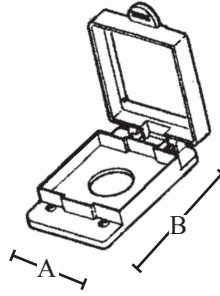

FEATURES

- Spring loaded lid; weather seal gasket
- Weatherproof cover when closed
- Cover must be matched to the capacity size of the receptacle

APPLICATIONS

- Fits a single receptacle; prevents damage from water and other elements

STANDARD MATERIAL

- PVC


PART #	SIZE	HOLE DIAMETER	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B
1317	15 AMP	1.375	10	3	2.8125"	4.5625"
1318	20 AMP	1.625	10	3	2.8125"	4.5625"
1319	30 AMP	1.722	10	3	2.8125"	4.5625"
1320	50 AMP	2.187	10	3	2.8125"	4.5625"

GFI RECEPTACLE COVER

SINGLE



1321

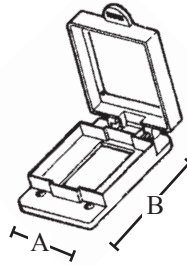

FEATURES

- Spring loaded lid; weather seal gasket
- Weatherproof cover when closed
- Cover must be matched to the capacity size of the receptacle

APPLICATIONS

- Fits a single gang FS type box and covers a standard ground fault interrupter receptacle

STANDARD MATERIAL

- PVC


PART #	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B
1321	10	3	2.8125"	4.5625"

DUPLEX RECEPTACLE COVER

SINGLE



1323

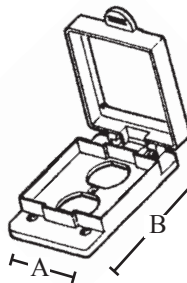

FEATURES

- Spring loaded lid; weather seal gasket
- Weatherproof cover when closed
- Cover must be matched to the capacity size of the receptacle

APPLICATIONS

- Fits a single gang FS type box and covers a standard ground fault interrupter receptacle

STANDARD MATERIAL

- PVC

PART #	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B
1323	10	3	2.8125"	4.5625"


WEATHERPROOF

TOGGLE SWITCH COVER

SINGLE



1316

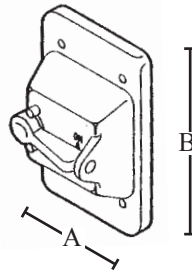

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
1316	10	2	2.8125"	4.5625"

FEATURES

- Weatherproof cover fits a single gang FS type box

APPLICATIONS

- Toggle arm operates a standard 115 volt single or double pole switch which is completely enclosed

STANDARD MATERIAL


- PVC

PLUNGER SWITCH COVER

SINGLE



1326

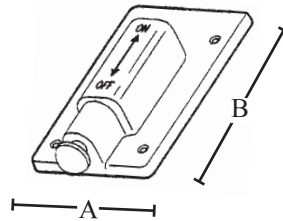

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
1326	10	3	2.8125"	4.5625"

FEATURES

- Weatherproof cover fits a single gang FS type box

APPLICATIONS

- Plunger operates a standard single or double pole 115 volt switch which is completely enclosed

STANDARD MATERIAL


- PVC

SWITCH COVER

SINGLE



1315

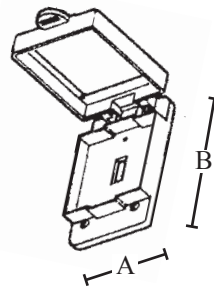

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
1315	10	3	2.8125"	4.5625"

FEATURES

- Weatherproof cover when closed

APPLICATIONS

- Fits a single gang FS type box and covers a single or double pole standard 115 volt switch

STANDARD MATERIAL

- PVC


WEATHERPROOF

BLANK COVER

SINGLE



1313TZ

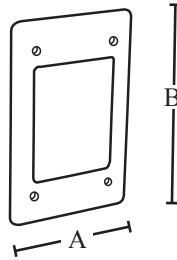

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
1313TZ	50	6	2.875"	4.5625"

FEATURES

- Companion to Topaz single PVC boxes
- Rust proof; corrosion resistant

APPLICATIONS

- For use with a single gang FS type box


STANDARD MATERIAL

- PVC

DOUBLE



1314

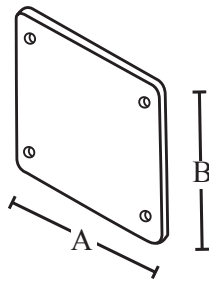

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
1314	25	5	4.5625"	4.5625"

FEATURES

- Companion to Topaz double PVC boxes
- Rust proof; corrosion resistant

APPLICATIONS

- For use with a double gang FS type box

STANDARD MATERIAL


- PVC

TWO TOGGLE SWITCH COVER

DOUBLE



1324

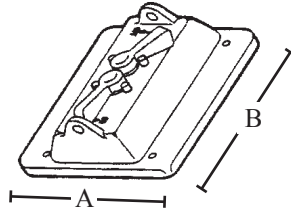

FEATURES

- Weatherproof when closed
- Easy to access toggle arms operate the enclosed switches

APPLICATIONS

- Fits double gang FB box that encloses 2 single or double pole 115 volt standard switches

STANDARD MATERIAL

- PVC


PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
1324	10	3	4.5625"	4.5625"

DUPLEX & TOGGLE SWITCH COVER

DOUBLE



1325

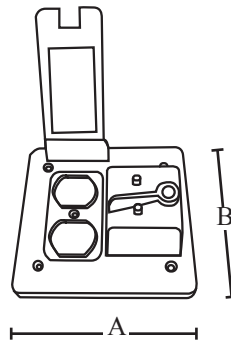

FEATURES

- Spring loaded lid; weather seal gasket
- Weatherproof cover when closed
- Cover must be matched to the capacity size of the receptacle

APPLICATIONS

- Fits a double gang FS type box and covers a standard ground fault interrupter receptacle
- Covers 1 single or double pole 115 volt switch & 1 standard 115 volt duplex receptacle

STANDARD MATERIAL

- PVC

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
1325	10	3	4.5625"	4.5625"


WEATHERPROOF

FD TYPE BOX

BLANK - SINGLE



1281

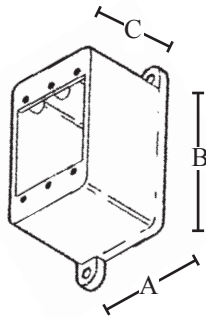

PART #	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1281	10	4	2.875"	4.5625"	2.375"

FEATURES

- Mounting feet enable easy installation
- Accommodates standard covers and accessories

APPLICATIONS

- Commonly used for tele-communications applications
- Use for terminations where hub requirements vary

STANDARD MATERIAL


- PVC

FSE TYPE BOXES

SINGLE



1282

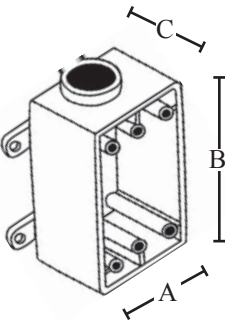

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1282	1/2"	10	5	2.875"	4.5625"	2.375"
1283	3/4"	10	5	2.875"	4.5625"	2.375"
1284	1"	10	4	2.875"	4.5625"	2.375"

FEATURES

- Mounting feet enable easy installation
- Accommodates standard covers and accessories
- Surface mounted electrical box which has only one conduit entrance hub with no outlet hub

APPLICATIONS

- Use for dead end terminations

STANDARD MATERIAL


- PVC

FSC TYPE BOXES

SINGLE



1288

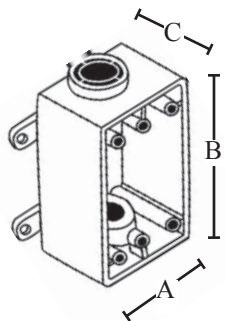

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1288	1/2"	10	5	2.875"	4.5625"	2.375"
1289	3/4"	10	5	2.875"	4.5625"	2.375"
1290	1"	10	5	2.875"	4.5625"	2.375"

FEATURES

- Mounting feet enable easy installation
- Accommodates standard covers and accessories
- Surface mounted electrical box which has one conduit entrance hub in each of the two short walls of the box

APPLICATIONS

- Use for straight line conduit runs, splices and through terminations
- Uses single gang electrical device cover

STANDARD MATERIAL


- PVC

FSS TYPE BOXES

SINGLE



1294

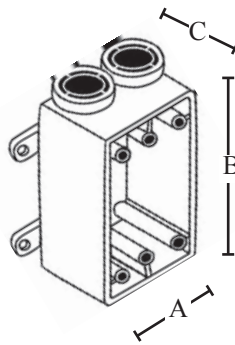

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1294	1/2"	10	5	2.875"	4.5625"	2.375"
1295	3/4"	10	5	2.875"	4.5625"	2.375"
1296	1"	10	4	2.875"	4.5625"	2.375"

FEATURES

- Mounting feet enable easy installation
- Accommodates standard covers and accessories
- Surface mounted electrical box which has two conduit entrance hubs on one short wall of the box only

APPLICATIONS

- Use for straight line conduit runs, splices and for multiple dead end circuit terminations
- Ideal when additional support is required for stub ups
- Uses single gang electrical device cover

STANDARD MATERIAL


- PVC

FSCC TYPE BOXES

SINGLE



1301TZ

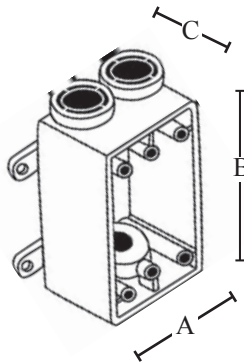

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1301TZ	1/2"	10	5	2.875"	4.5625"	2.375"
1302TZ	3/4"	10	5	2.875"	4.5625"	2.375"
1303	1"	10	4	2.875"	4.5625"	2.375"

FEATURES

- Mounting feet enable easy installation
- Accommodates standard covers and accessories
- Surface mounted electrical box that has two conduit entrance hubs in one wall of the box and one hub in the opposite wall

APPLICATIONS

- Use for straight line conduit runs, splices and multiple through terminations
- Ideal when additional support is required for stub ups
- Uses single gang electrical device cover

STANDARD MATERIAL

- PVC


WEATHERPROOF

FDC TYPE BOXES

SINGLE



1307

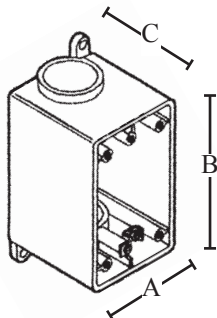

FEATURES

- Surface mounted electrical box with grounding lug has one conduit entrance hub in each of the two short walls of the box

APPLICATIONS

- Use for straight line conduit runs and splices
- Uses single gang electrical device cover

STANDARD MATERIAL

- PVC


PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1307	1/2"	10	6	2.875"	4.5625"	3"
1308	3/4"	10	6	2.875"	4.5625"	3"
1309	1"	10	5	2.875"	4.5625"	3"

FDS TYPE BOXES

SINGLE



1310

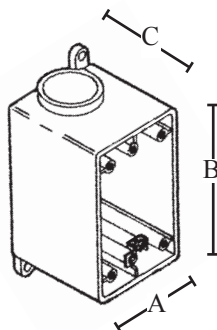

FEATURES

- Surface mounted electrical box with grounding lug has one conduit hub on short wall side

APPLICATIONS

- Use for straight line conduit runs and splices
- Uses single gang electrical device cover

STANDARD MATERIAL


- PVC

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1310	1/2"	10	4	2.875"	4.5625"	3"
1311	3/4"	10	6	2.875"	4.5625"	3"
1312	1"	10	5	2.875"	4.5625"	3"


WEATHERPROOF

FSE TYPE BOXES

DOUBLE

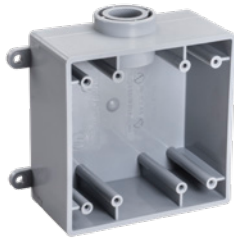

1285

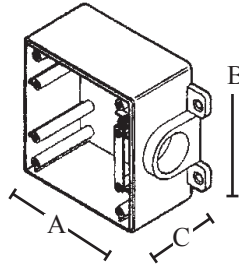

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1285	1/2"	5	3	4.5625"	4.5625"	2.375"
1286	3/4"	5	3	4.5625"	4.5625"	2.375"
1287	1"	5	3	4.5625"	4.5625"	2.375"

FEATURES

- Mounting feet enable easy installation
- Accommodates standard covers and accessories
- Surface mounted electrical box which has only one conduit entrance hub with no outlet hub

APPLICATIONS

- Use for dead end terminations
- Uses double gang device covers

STANDARD MATERIAL


- PVC

FSC TYPE BOXES

DOUBLE



1291

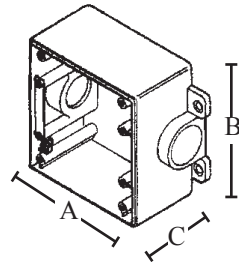

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1291	1/2"	5	4	4.5625"	4.5625"	2.375"
1292	3/4"	5	4	4.5625"	4.5625"	2.375"
1293	1"	5	3	4.5625"	4.5625"	2.375"

FEATURES

- Mounting feet enable easy installation
- Accommodates standard covers and accessories
- Surface mounted electrical box which has one conduit entrance hub in each of the two opposite walls of the box

APPLICATIONS

- Use for straight line conduit runs, splices and through terminations
- Uses double gang electrical device cover

STANDARD MATERIAL

- PVC


WEATHERPROOF

FSS TYPE BOXES

DOUBLE



1297

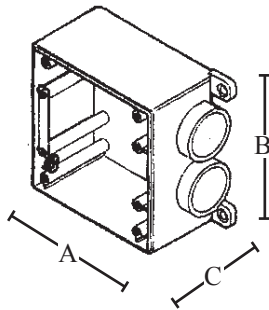

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1297	1/2"	5	4	4.5625"	4.5625"	2.375"
1298	3/4"	5	3	4.5625"	4.5625"	2.375"
1299	1"	5	3	4.5625"	4.5625"	2.375"

FEATURES

- Detachable mounting feet enable easy installation
- Accommodates standard covers and accessories
- Surface mounted electrical box which has two conduit entrance hubs on one wall of the box only

APPLICATIONS

- Use for straight line conduit runs, splices and for multiple dead end circuit terminations
- Ideal when additional support is required for stub ups
- Uses double gang electrical device cover

STANDARD MATERIAL


- PVC

FSCC TYPE BOXES

DOUBLE



1304

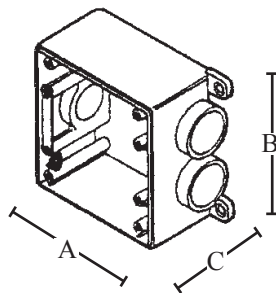

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
1304	1/2"	5	4	4.5625"	4.5625"	2.375"
1305	3/4"	5	4	4.5625"	4.5625"	2.375"
1306	1"	5	3	4.5625"	4.5625"	2.375"

FEATURES

- Mounting feet enable easy installation
- Accommodates standard covers and accessories
- Surface mounted electrical box that has two conduit entrance hubs in one wall of the box and one hub in the opposite wall

APPLICATIONS

- Use for straight line conduit runs, splices and multiple through terminations
- Ideal when additional support is required for stub ups
- Uses double gang electrical device cover

STANDARD MATERIAL


- PVC

WEATHERPROOF

JUNCTION BOXES



1221

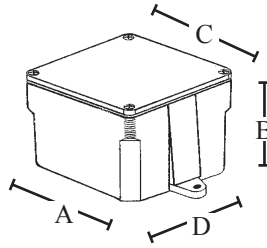

FEATURES

- NEMA 3 rated where indicated
- A surface mounted enclosure without entrance hubs which allows multiple conduits to be connected and wire splices made within

APPLICATIONS

- Appropriate round hole for conduit entrance must be cut
- Male adapters or box adapters may be used to secure conduit to the box
- May be concrete encased or buried (not warranted or listed to be watertight for all circumstances)

STANDARD MATERIAL

- PVC
- Screws - Zinc plated steel

PART #	INSIDE DIMENSION	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C	D
1221*	4" x 4" x 2"	10	7	4.375"	2.375"	4.375"	4.375"
1222*	4" x 4" x 4"	10	11	4.25"	4.375"	4.25"	4.25"
1223*	4" x 4" x 6"	10	15	4.25"	6.3125"	4.25"	4.25"
1224*	5" x 5" x 2"	10	9	5.25"	2.3125"	5.25"	5.25"
1225TZ*	6" x 6" x 4"	10	23	6.375"	4.375"	6.75"	6.375"
1226*	6" x 6" x 6"	5	14	6.375"	6.3125"	6.6875"	6.375"
1227*	8" x 8" x 4"	5	18	8.50"	4.50"	8.875"	8.50"
1228	8" x 8" x 6"	4	18	8.3125"	6.4375"	9"	8.3125"
1229*	8" x 8" x 7"	4	21	8.75"	7.75"	9"	8.75"
1230TZ*	12" x 12" x 4"	2	14	12.50"	4.4375"	12.875"	12.50"
1231*	12" x 12" x 6"	2	18	12.375"	6.50"	12.875"	12.375"
1232*	16" x 14" x 6"	1	12	16.75"	6.75"	17.125" x 15.125"	14.75"
1233**	24" x 18" x 8"	1	23	24.125"	8.25"	24.25" x 18.75"	18.25"
1234†	24" x 24" x 8"	1	36	24.25"	8.25"	24.1875"	24.25"
1235TZ†	36" x 24" x 8"	1	34	24.25"	8.25"	24.25" x 36.25"	36.25"

* NEMA 3 rated

** UL listed with only a Type 1 NEMA rating

† Not UL listed

WEATHERPROOF

VAPORPROOF FIXTURES



FEATURES

- Ceiling, wall or pendant mounting
- All assembled fixtures are equipped with 5 holes and available with 1/2" & 3/4" threaded holes
- Socket with leads
- Heat resistant glass globe
- Prevents moisture entry
- Industrial grade, fully gasketed
- Designed to protect the interior from deteriorating effect of ice, corrosive fumes, and non-explosive vapors
- Gray

APPLICATIONS


- UL listed for wet locations
- Maintains illumination for safety and performance in inclement weather
- Input Voltage: 120V

STANDARD MATERIAL

- Rugged die cast copper free aluminum

STANDARD FINISH

- Premium powder coat finish

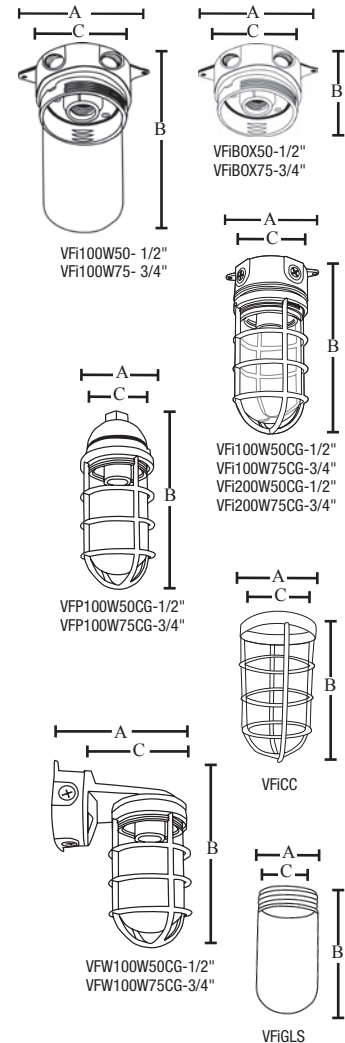

PART #	# OF HOLES	THREAD SIZE	SHIP CASE	WEIGHT/ CASE (LBS.)	A	B	C
VF100W50*	5	1/2"	6	13	5.25"	8.50"	3.25"
VF100W75*	5	3/4"	6	13	5.25"	8.50"	3.25"
VF100W50CG*	5	1/2"	6	16	5.25"	9"	4.13"
VF100W75CG*	5	3/4"	6	16	5.25"	9"	4.13"
VF200W50CG**	5	1/2"	6	16	5.25"	11.50"	5.15"
VF200W75CG**	5	3/4"	6	16	5.25"	11.50"	5.15"
VFIBOX50	5	1/2"	12	13	5.25"	3.50"	4.13"
VFIBOX75	5	3/4"	12	13	5.25"	3.50"	4.13"
VFP100W50CG*	-	1/2"	6	16	4.13"	10.25"	3.88"
VFP100W75CG*	-	3/4"	6	16	4.13"	10.25"	3.88"
VFW100W50CG*	5	1/2"	6	19	7.25"	10"	4.13"
VFW100W75CG*	5	3/4"	6	19	7.25"	10"	4.13"
VAPORPROOF 7" GLASS GLOBE							
VFIGLS			6	6	3.25"	7"	3"
7" CAST CAGE							
VFICCS			16	11	4.25"	7.25"	4.13"

UL Listing:

Suitable for wet locations for use in dwellings. Suitable for use with 90° C supply wiring. Complies with UL Standard 1598. For non-hazardous locations where the lamp, socket and wiring require protection from rain, corrosive fumes, non-explosive vapors and gases.

*Approved for maximum 100W incandescent. **Approved for maximum 200W incandescent.

WEATHERPROOF



Southwire™

WEATHERPROOF CATALOG

get social with us:



[/SOUTHWIRETOOLS](#)



[/SOUTHWIRE-COMPANY](#)



[@SOUTHWIRETOOLS](#)



[@SOUTHWIRE](#)



SCAN TO LEARN MORE

WWW.SOUTHWIRE.COM | 1-855-SWTTOOLS

All Trademarks or Registered Trademarks (TM/®) are owned or licensed by Southwire Company.
Any other TM/®- Trademark or Registered Trademark of Southwire Company.