



Southwire™

# TEMPORARY LIGHTING SOLUTIONS CATALOG



**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

[SOUTHWIRE.COM](http://SOUTHWIRE.COM)

# OUR STORY

As a family business, Southwire proudly continues building on our commitment to environmental stewardship and corporate sustainability by prioritizing stakeholder expectations, and supporting the wellbeing of our communities and the environment in which we live. To help us meet this commitment, we organize our sustainability strategy around five core tenets: Growing Green, Living Well, Giving Back, Doing Right, and Building Worth.

## ***We Deliver Power...Responsibly®***

We remain committed to the sustainability of our company for the next 100 years and beyond. As we strengthen this commitment, we continue to work hard every day to discover, develop and distribute sustainable solutions that exceed the expectations of our stakeholders around the world.

## **OUR MISSION**

To be a **preferred provider** of solutions to the electrical industry by providing innovative products and services with exceptional quality.

## **OUR VALUES**

Our **ONE Southwire** culture prioritizes the interests of our team members, customers, and communities through a continuous commitment to empowerment, trust, consistency, and inclusion.

## **OUR REACH**

Nearly one in two new homes built in the United States contains our wire, and we produce half of the cable used to transmit and distribute electricity throughout the nation.

## **OUR PRODUCTS**

Our product teams and dedicated resources work together to listen to and work with our customers, creating solutions that deliver unparalleled value through product innovation, safety and efficiency.

## **OUR SERVICE**

Service is more than a word or a phone number; it's a tangible support system that assists you through the entire project cycle; from our knowledgeable customer service team, to our experienced field sales team, we're there every step of the way.



# TABLE OF CONTENTS

## TEMPORARY LIGHTING

Area Lights.....	4
Overhead Lights.....	10
String Lights .....	23
Cart Lights .....	30
Work Lights.....	32
Personal Lighting.....	38
Clamps & Trouble Lights.....	41
Installed Lighting .....	44
Hazardous Location .....	46

# AREA LIGHTS

The Southwire Area Lighting range is built to offer maximum lumen output for large projects, while still keeping lighting at ground level. Included in this category group is the Wobblelight product group, featuring self-righting technology, and the ability to output light at 360°. Additionally, the balloon light category offers the latest in LED technology on heavy-duty stands to ensure the light is away from eye level. Southwire can light any jobsite with the perfect 360° lighting solution for you.



# AREA LIGHTS



For 20 years, the Wobblelight® has provided reliable lighting on the jobsite. The self-righting technology paired with heavy-duty housing guarantees these products will provide years of service in the toughest environments.



**360° OF LIGHT**

**INTEGRATED HANDLE**

**DURABLE RESIN HOUSING**

**COVERED SOCKET**

**SELF-RIGHTING BASE**

**WOBBLELIGHT®**

# AREA LIGHTS

## LED WOBBLELIGHT®



111301LED

- 120V
- 5000K color temperature
- Operating temp: -40°F to 125°F
- 5-15 plug

### SPECIFICATIONS



MODEL #	DESCRIPTION	BODY STYLE	WATTS	LAMP LIFE	LINKABLE UNITS	AMP DRAW	CORD TYPE	IP RATING	WEIGHT
111301LED	12,000 lumen 32" LED Wobblelight	32"	150W	50,000 hrs.	6 Max	1.25A	5' 16/3 SJ00W	IP54	31 lbs.
111303LED	15,000 lumen 32" LED Wobblelight	32"	220W	50,000 hrs.	-	1.8A	5' 16/3 SJ00W	IP55	31 lbs.

## 10,000 LUMEN SELF-RIGHTING LED JOBSITE LIGHT



- Daisy chain socket
- Patented self-righting technology
- 360° light output
- 5' power cord
- Intergrated carrying handle
- Heavy-duty steel dome design
- 10,000 lumens | 120Vac 50/60Hz | 90 watts E39 mogul base

### SPECIFICATIONS

MODEL #	DESCRIPTION	BODY STYLE	WATTS	LAMP LIFE	LINKABLE UNITS	AMP DRAW	CORD TYPE	IP RATING	WEIGHT
111211	10,000 Lumen Self-Righting LED Jobsite Light	27"	90	35,000 hrs.	4	0.75A	SJTW	--	18 lbs.

# AREA LIGHTS

## 6,000 LUMEN SELF-RIGHTING LED JOBSITE LIGHT



- Patented self-righting technology
- 360° light output
- 5' power cord
- Intergrated carrying handle
- No hot surfaces
- 5000K color temperature
- 6,000 lumens | 120Vac 50/60Hz | 51 watts E39 mogul base

### SPECIFICATIONS

MODEL #	DESCRIPTION	BODY STYLE	WATTS	LAMP LIFE	LINKABLE UNITS	AMP DRAW	CORD TYPE	IP RATING	WEIGHT
111208	6,000 Lumen Self-Righting LED Jobsite Light	25"	51	35,000 hrs.	--	0.42A	SJTW	--	16 lbs.

WOBBLELIGHT®

# AREA LIGHTS


## WOBBLELIGHT® ACCESSORIES AND REPLACEMENT BULBS.

### SPECIFICATIONS

MODEL #	DESCRIPTION	WORKS WITH
111908	85W Fluorescent Bulb	11205
111904	500W Halogen Bulb	111302
111903	400W Metal Halide Bulb	111104
111807	Nylon Reflector Shield	111203, 111204, 111205, 111206
111808	Nylon Reflector Shield	111301LED, 111303LED, 111302, 111102, 111104
111801	Replacement Reflector Dome and Cap	111302, 111102, 111104
1113186	Replacement Reflector Dome and Cap	111301LED, 111303LED
65151701	Replacement Dome and Cap	111205, 111206

\*ADDITIONAL INTERNAL REPLACEMENT PARTS AVAILABLE

## WOBBLELIGHT® 360° LIGHT DISTANCE

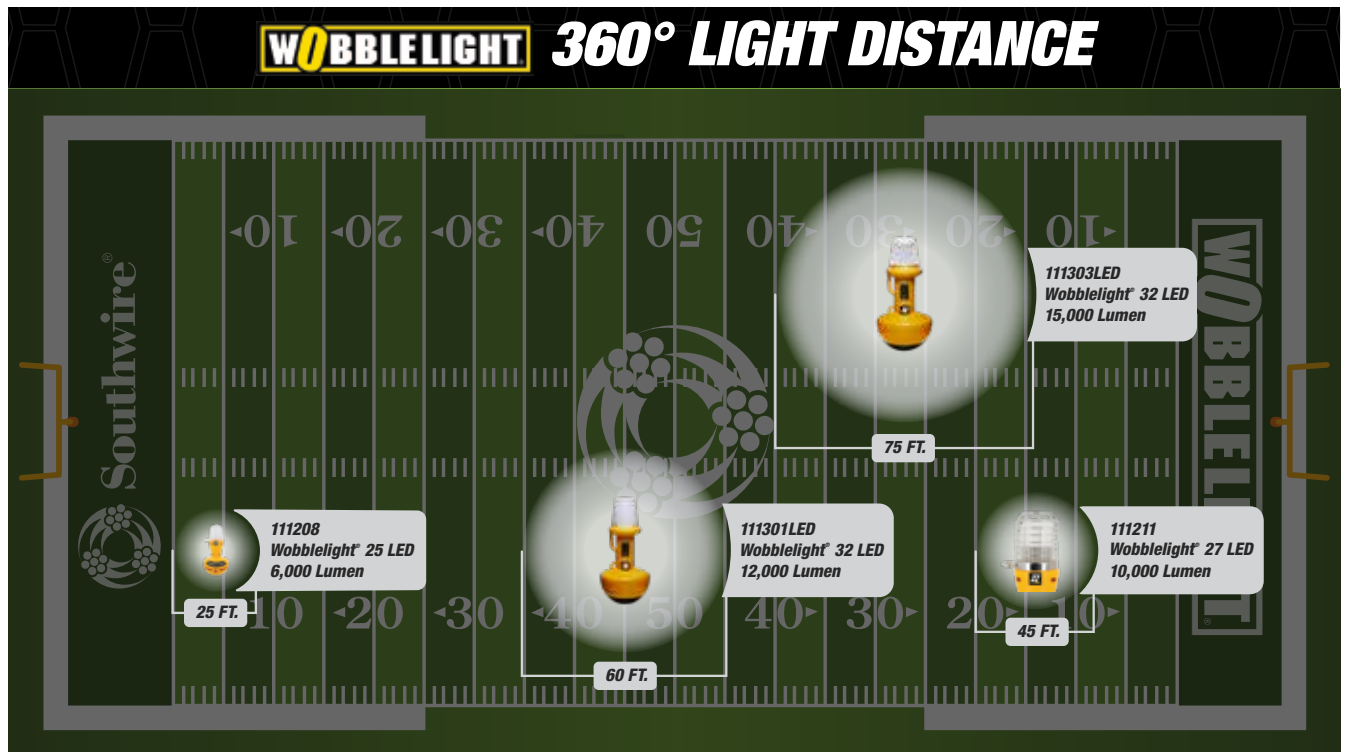

WOBBLELIGHT®



# AREA LIGHTS

## 120W 360° INDUSTRIAL LIGHT



111508


- 5000K color temperature
- Integrated cord
- 360° and 180° illumination
- 7,500 and 15,000 lumen range

### SPECIFICATIONS



MODEL #	DESCRIPTION	LIGHT TEMPERATURE	IP RATING	WATTS	CORD	FEATURES
111508	15,000 Lumens ProLight™ 360° LED Light Kit	5,000K	IP65	120W	5' - 18/3 SJTW Cord	Included: Floor Stand Tripod Mount, Hook, Two Earth Magnets
111509	15,000 Lumens ProLight™ 360° LED Light Kit with Tripod	5,000K	IP65	120W	5' - 18/3 SJTW Cord	Included: Floor Stand Tripod Mount, Hook, Two Earth Magnets Heavy Duty Tripod
TLU-100	12,000 Lumen LED Lanterns	5,000K	--	100W	10' Cord	Included: Hook, Magnet, Tripod Adapter, and Paint Shield

### PROLIGHT™ 360° KIT FEATURES (111508 & 111509)

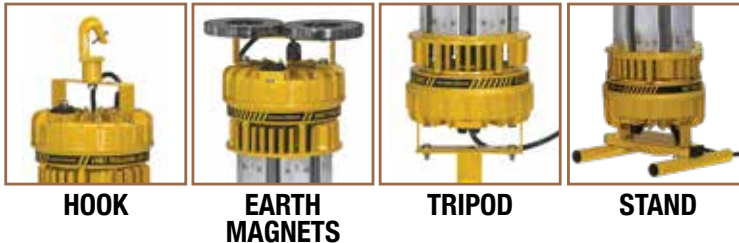

HOOK

EARTH  
MAGNETS

TRIPOD

STAND

## BALLOON LIGHT



9822

- Soft diffused glare-free light
- Illuminates 11,000 sq. ft.
- Rated for wet locations
- 125V
- Collapsible flame retardant fabric balloon and 9' tripod
- 15' 16/3 SJTOW cord with 5-15 plug with in-line switch
- Kit includes: tripod, LED lights head and 2 x fabric balloon covers

### SPECIFICATIONS



MODEL #	DESCRIPTION	BODY STYLE	WATTS	AMPS
9822	24,000 Lumen LED Balloon Light	Tripod	200	1.62

360° LED LIGHTS

# OVERHEAD JOBSITE LIGHTING

---

Southwire offers a full range of overhead jobsite lighting options with an array of different light distribution models. Whether you need directional lighting or a broader distribution of light, Southwire has the perfect option for you. When considering overhead lighting, make sure to check out our Southwire Lighting Solutions; including Customized Lighting, Lighting Layout Services, and our Ready-2-Hang bulk packaging.




# OVERHEAD JOBSITE LIGHTING

## T60 SERIES

**OPTICAL ADVANTAGE:** Distributes light in all directions

**WHY:** General purpose lights where wall illumination or ceiling work may be important

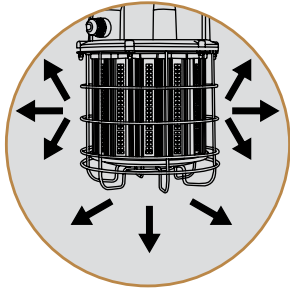

**INTEGRAL HOOK FOR EASY HANGING**

**DAISY CHAINABLE CORDS WITH LENGTH OPTIONS**

**INTEGRAL LEDS**

**PROTECTIVE CAGE**




T60100

## CL SERIES

**OPTICAL ADVANTAGE:** Broad distribution of light but delivers more light to the ground

**WHY:** General purpose scenarios where efficient ground illumination is also a priority

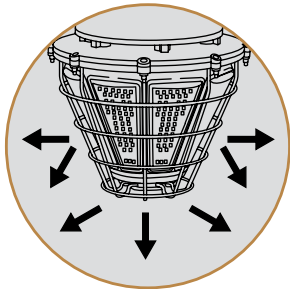

**INTEGRAL HOOK FOR EASY HANGING**

**DAISY CHAINABLE CORDS WITH LENGTH OPTIONS**

**ANGLED INTEGRAL LEDS**



CL100LEDG2

360° JOBSITE LIGHTS

# OVERHEAD JOBSITE LIGHTING

## T6 SERIES INTEGRATED LED OVERHEAD LIGHTS



T60100

- 16/3 Cord
- 5000K, 80 CRI
- 50,000 hour rated LED life
- 120V
- Integral hook
- Damp location rated

### SPECIFICATIONS



MODEL #	DESCRIPTION	WATTS	SQ. FT. COVERAGE (AT 5 FC, HUNG AT 15FT)	AMP DRAW	MAX LINKABLE UNITS	FEEDTHROUGH	COLOR
T60100	15,000 Lumen Integrated LED Cage Light	100W	2,000	0.83	7	10' - Plug and 1' - Receptacle	Copper
T60100W35	15,000 Lumen Integrated LED Cage Light	100W	2,000	0.83	5	35' - Plug and 1' - Receptacle	Copper
T60150	22,500 Lumen Integrated LED Cage Light	150W	2,646	1.25	5	10' - Plug and 1' - Receptacle	Copper
T60150W45	22,500 Lumen Integrated LED Cage Light	150W	2,646	1.25	3	45' - Plug and 1' - Receptacle	Copper

## T5 SERIES INTEGRATED LED OVERHEAD LIGHTS



T50078

- 5000K
- 120/277V
- Rugged die-cast aluminum housing
- 50,000 hour rated LED life
- Damp location rated

### SPECIFICATIONS



MODEL #	DESCRIPTION	WATTS	SQ. FT. COVERAGE (AT 5 FC, HUNG AT 15FT)	AMP DRAW	FEEDTHROUGH	COLOR
T50078	8,200 Lumen Temporary Low Bay LED Light, 120/277	78W	1,600	0.65	3' - Plug Only	Copper
T50079	8,200 Lumen Temporary Low Bay LED Light, Direct Wire	78W	1,600	0.65	3' - Direct Wire	Copper

## CL120 SERIES INTEGRATED LED OVERHEAD LIGHTS



CL120LED

- 16/3 cord
- 4800K
- 120/277V
- 50,000 hour rated LED life
- Polycarbonate lens cover
- Damp location rated

### SPECIFICATIONS



MODEL #	DESCRIPTION	WATTS	SQ. FT. COVERAGE (AT 5 FC, HUNG AT 15FT)	AMP DRAW	MAX LINKABLE UNITS	FEEDTHROUGH	COLOR
CL120LED	14,000 Lumen Integrated LED Cage Light, Angled LED Panel	120W	2,500	1	7	5' - Plug and receptacle	Yellow
CL120LED-W	14,000 Lumen Integrated LED Cage Light, Angled LED Panel	120W	2,500	1	7	5' - Plug and receptacle	White

360° LED LIGHTS

# OVERHEAD JOBSITE LIGHTING

## PREFAB LED LANTERNS



T90200

Southwire prefab lanterns come in 4 different lumen models, each model, and has a custom wiring terminal allowing you to add your own cords to fit your specific needs. When wiring, you can use the provided strain relief connectors or the 1/2" threaded hubs designed to fit other Southwire fittings. Each model includes a retractable handle for ceiling mounting and low-profile stacking.

- Cord-free custom wiring terminal
- Accepts 12-gauge through 16-gauge SO cord
- 1/2" threaded hub for Southwire fittings
- Accepts most sizes of Romex® Brand and MC cable when used with correct fitting
- Includes steel 2x strain relief connectors
- Retractable hanging clip for low profile
- Made with a stackable design
- Replaceable fixture head & wiring terminal
- 5000K CCT
- 120V - 277VAC 50/60 HZ
- Custom wiring terminal block
- 3-in-1 dimmer (200W model)
- Outdoor weather rated (when used with weatherproof connectors)



T90150

### SPECIFICATIONS




MODEL #	DESCRIPTION	LUMENS	HEIGHT	WIDTH	LENGTH	WEIGHT
T90060	60W PreFab LED Lantern	9,000	10.44"	6.5"	6.5"	6 lbs.
T90100	100W PreFab LED Lantern	15,000	11.44"	6.5"	6.5"	6.5 lbs.
T90150	150W PreFab LED Lantern	22,500	12.54"	6.5"	6.5"	7 lbs.
T90200	200W PreFab LED Lantern	30,000	15.88"	6.5"	6.5"	7.5 lbs.



T90100

### WIRING TERMINAL

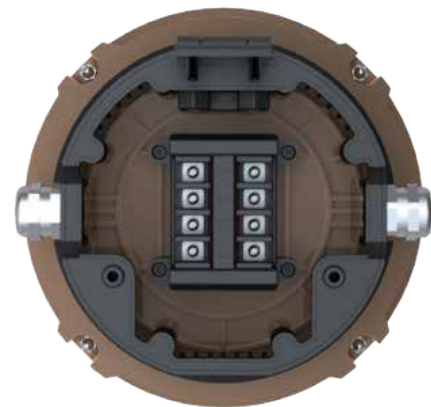

T90060

PREFAB LED LANTERNS

# OVERHEAD JOBSITE LIGHTING

## CL SERIES SECOND GEN INTEGRATED LED OVERHEAD LIGHTS



CL100LED

- 16/3 cord
- 5000K
- 120/277V

- 50,000 hour rated LED life
- Polycarbonate lens cover
- Operating temperature: -20°F to 140°F

- Damp location rated

### SPECIFICATIONS



MODEL #	DESCRIPTION	WATTS	SQ. FT. COVERAGE AT 5 FC, HUNG AT 15FT	AMP DRAW	MAX LINKABLE UNITS	FEEDTHROUGH	COLOR
CL60LED	7,800 Lumen Integrated LED Cage Light, Angled LED Panel	60W	1,320	0.5	9	5' - Plug Only	Orange
CL60LEDG2	7,800 Lumen Integrated LED Cage Light, Angled LED Panel	60W	1,320	0.5	9	6' - Plug and 1' - Receptacle	Orange
CL100LEDG2	13,000 Lumen Integrated LED Cage Light, Angled LED Panel	100W	2,000	0.83	7	6' - Plug and 1' - Receptacle	Orange
CL100LEDG2W	12,000 Lumen Integrated LED Cage Light, Angled LED Panel	100W	2,000	0.83	7	6' - Plug and 1' - Receptacle	White
CL100LED	13,000 Lumen Integrated LED Economy Cage Light	100W	2,600	1.25	7	6' - Plug and Receptacle	Orange

## TEMPORARY HIGH BAY



17100LEDP3

- 120V/277VAC 50/60Hz
- Includes 6' power cord and 20" safety cable
- Vibration, shock, and impact resistant
- Damp location rated

- Self-locking hook/carry handle
- M8 screw thread for easy use with tripod or eyebolt ring
- Optional tripod for quick set-up

### SPECIFICATIONS



MODEL #	DESCRIPTION	LUMENS	WATTS	SQ. FT. COVERAGE	AMP DRAW	FEEDTHROUGH	COLOR
17100LEDP3	100W Temporary High Bay	12,000	100W	2,000	1A	6' - plug only	Yellow
17150LEDP3	150W Temporary High Bay	18,000	150W	2,600	1.5A	6' - plug only	Yellow

HANGING LIGHT

# OVERHEAD JOBSITE LIGHTING

## JOBSITE OVERHEAD LIGHTING LAYOUT SERVICES

OSHA standard 1926.56(a) requires a jobsite to have 5 foot candles of light on the ground. Southwire can help you with your lighting layout to ensure that you keep your crew safe without overspending on unnecessary lights.

Contact your Southwire sales associate for more information about Southwire's Lighting Layout Tool  
**EMAIL: [LIGHTING@SOUTHWIRE.COM](mailto:LIGHTING@SOUTHWIRE.COM)**

- Keep your jobsite safe with the right amount of light
- Avoid over-lighting a space and increasing install time
- Reduce your material spend



## LET SOUTHWIRE LAYOUT YOUR JOBSITE LIGHTING

### WHAT WE NEED FROM YOU

- **PROJECT DIMENSIONS:** Length x Width x Deck Height
- **REQUESTED FOOT CANDLE LEVEL:** How many foot candles do you need on your project?
- **WE CAN USE YOUR DRAWINGS TO CALCULATE JOBSITE DIMENSIONS:** Either .PDF or .IFC files


LIGHTING LAYOUT SERVICES

# OVERHEAD JOBSITE LIGHTING

## READY2HANG LIGHTING PROGRAM

### INCREASE YOUR LIGHTING INSTALL EFFICIENCY

By reducing install time with Southwire's Ready2Hang Lighting Program.

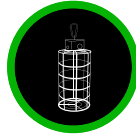

PRE-ASSEMBLED



SHIPPED COMPLETE TO YOUR JOBSITE



READY TO HANG ON YOUR JOBSITE

### PROGRAM DETAILS

*\*Order minimum: 50+ pieces*

#### SERVICES INCLUDES

- The Ready2Hang service does not extend lead times
- LED bulbs come fully installed to save you time
- Assembled fixtures are removed from cardboard boxes
- Safely shipped in easily removed bubble wrap packing



REDUCE JOBSITE WASTE & CLEAN UP TIME WITH MINIMAL PRODUCT PACKAGING



ELIMINATE LIGHT FIXTURE ASSEMBLY TIME



INCREASE INSTALL SPEED WITH CUSTOM LIGHT FIXTURES



PRE-ASSEMBLED



WRAPPED



PACKAGE



UNPACK



UNWRAP



INSTALL



READY2HANG



# OVERHEAD JOBSITE LIGHTING

## HANGING ACCESSORIES

Jobsites are complex. That's why it's essential to have the right product on hand to save you both time and money. Below you will find a list of Southwire products that are popular for use with our lanterns.



SC5075HF



CPMH1



JHK-32MAG



JHK-64



MCG-50A560



L-42-1

## SPECIFICATIONS

MODEL #	DESCRIPTION	FUNCTION
<b>TEMPORARY LIGHTING MOUNTING ACCESSORIES</b>		
SC-5075HF	4" Square Swivel Fixture Hanger Ring, with Hands Free Door	Provides a threaded mounting point for the fixture hook and convenient hands free door for direct wire applications
SC-507HFR	4" Round Swivel Fixture Hanger Ring, with Hands Free Door	Provides a threaded mounting point for the fixture hook and convenient hands free door for direct wire applications
SC-507511BHF	4-11/16" Round Swivel Fixture Hanger Ring, with Hands Free Door	Provides a threaded mounting point for the fixture hook and convenient hands free door for direct wire applications
CPMH1	Cage Light Fixture Hook with Threaded End	Pairs with swivel fixture hangers to provide a hanging surface for the light
JHK-32MAG	2" J Hook with 90 lb. Magnet	Supporting and managing string light or extension cord cables
JHK-64	2" J Hook with Mounting Hole	Supporting and managing string light or extension cord cables
JHK-32-AB	2" J Hook with Angled Bracket with Mounting Hole	Supporting and managing string light or extension cord cables
58299040	14" Reusable Cable Ties, Black, 15 Pack	Manage cables and hang small fixtures
58298740	14" Reusable Cable Ties, Black, 100 Pack	Manage cables and hang small fixtures
MCG-50A560	1/2" Cord Grip Steel	Connects and secures power supply to fixture
<b>CONNECTORS</b>		
BXCN50	1/2" Set Screw Connector for BX/MC Cable	Connects and secures power supply to fixture
L-42-1	1/2" Squeeze Box Connector Straight Zinc	Connects and secures power supply to fixture
L-41-1	1/2" Squeeze Box Connector Straight Zinc	Connects and secures power supply to fixture
L-48-1	1/2" Flex Set Screw Box Connector Zinc	Connects and secures power supply to fixture
MDB-50B	1/2" Double Bite Saddle Box Connector Straight Steel	Connects and secures power supply to fixture
IML-42-1	1/2" Flex/MC/AC Straight Squeeze Box Connectors, Insulated	Connects and secures power supply to fixture

PREFAB LED LANTERNS

# OVERHEAD JOBSITE LIGHTING

## CUSTOM LIGHT FIXTURE

### CREATE THE PERFECT OVERHEAD LIGHT TO FIT YOUR LIGHTING NEEDS

We understand that each jobsite has specific needs when it comes to custom light fixtures. That's why Garvin's light fixtures can be precisely designed for each job you have.



#### LUMENS

- 5,200
- 7,800
- 10,400
- 13,000
- 15,600
- 19,500
- 28,000

#### CORD GAUGE

- 16
- 14
- 12

#### CORD LENGTH

- 6 ft.
- 10 ft.
- Other \_\_\_\_\_



**NEMA  
5-15P**



**NEMA  
L5-15P**



**NEMA  
L7-15P**



MALE CORD END	FEMALE CORD END
none	none
515P-120V 15A 3 PRONG STRAIGHT BLADE	515P-120V 15A 3 PRONG STRAIGHT BLADE
L515-120V 15A TWIST LOCK	L515-120V 15A TWIST LOCK
L520-120V 20A TWIST LOCK	L520-120V 20A TWIST LOCK
L715-277V 15A TWIST LOCK	L715-277V 15A TWIST LOCK
L720-277V 20A TWIST LOCK	L720-277V 20A TWIST LOCK

CUSTOM LIGHTING

# OVERHEAD JOBSITE LIGHTING

## TEMPORARY LED CAGE LIGHTS

- 6500K color temperature
- 50,000 hour bulb life
- Replaceable bulbs



TL40LEDW

 


TL100LEDWS



TL200LEDWTL

### SPECIFICATIONS



MODEL #	DESCRIPTION	CORD	WATTS	VOLTS
TL40LED	5,200 Lumen Cage Light w/ medium base LED Corncob Bulb	None	40W	120-277V
TL40LEDW		6' w/ 5-15P Plug	40W	120V
TL40LEDWS		6' Direct Wire	40W	120-277V
TL40LEDWTL		6' w/ L7-15P Twist Lock Plug	40W	277V
TL40LEDPT		1' Cord w/ 5-15P Plug and 1' Cord w/ 5-15R Receptacle	40W	120V
TL60LED	7,800 Lumen Cage Light w/ medium base LED Corncob Bulb	None	60W	120-277V
TL60LEDW		6' w/ 5-15P Plug	60W	120V
TL60LEDWS		6' Direct Wire	60W	120-277V
TL60LEDWTL		6' w/ L7-15P Twist Lock Plug	60W	277V
TL60LEDPT		1' Cord w/ 5-15P Plug and 1' Cord w/ 5-15R Receptacle	60W	120V
TL80LED	10,400 Lumen Cage Light w/ LED Corncob Bulb	None	80W	120-277V
TL80LEDW		6' w/ 5-15P Plug	80W	120V
TL80LEDWS		6' Direct Wire	80W	120-277V
TL80LEDWTL		6' w/ L7-15P Twist Lock Plug	80W	277V
TL100LEDW	13,000 Lumen Cage Light w/ mogul base LED Corncob Bulb	6' w/ 5-15P Plug	100W	120V
TL100LEDWS		6' Direct Wire	100W	120-277V
TL100LEDWTL		6' w/ L7-15P Twist Lock Plug	100W	277V
TL100LEDPT		1' Cord w/ 5-15P Plug and 1' Cord w/ 5-15R Receptacle	100W	120V
TL120LED	15,600 Lumen Cage Light w/ mogul base LED Corncob Bulb	None	120W	120-277V
TL120LEDW		6' w/ 5-15P Plug	120W	120V
TL120LEDWS		6' Direct Wire	120W/120-277V	120-277V
TL120LEDWTL		6' w/ L7-15P Twist Lock Plug	120W/277V	277V
TL120LEDPT		1' Cord w/ 5-15P Plug and 1' Cord w/ 5-15R Receptacle	120W/120V	120V
TL150LED	19,500 Lumen Cage Light w/ mogul base LED Corncob Bulb	None	150W	120-277V
TL150LEDW		6' w/ 5-15P Plug	150W	120V
TL150LEDWS		6' Direct Wire	150W	120-277V
TL150LEDWTL		6' w/ L7-15P Twist Lock Plug	150W	277V
TL150LEDPT		1' Cord w/ 5-15P Plug and 1' Cord w/ 5-15R Receptacle	150W	120V
TL200LED	28,000 Lumen Cage Light w/ mogul base LED Corncob Bulb	None	200W	120-277V
TL200LEDW		6' w/ 5-15P Plug	200W	120V
TL200LEDWS		6' Direct Wire	200W	120-277V
TL200LEDWTL		6' w/ L7-15P Twist Lock Plug	200W	277V
TL200LEDPT		1' Cord w/ 5-15P Plug and 1' Cord w/ 5-15R Receptacle	200W	120V

LED CAGE LIGHTS

# OVERHEAD JOBSITE LIGHTING

## TEMPORARY FLUORESCENT CAGE LIGHTS



TL105CFPT

- 105W
- 8,000 hour bulb life
- Mounting hook & steel cage

### SPECIFICATIONS



MODEL #	DESCRIPTION	CORD END	VOLTS	BULB BASE
TL105CF	6,400 Lumen, 105W Fluorescent Temporary Light	None	120V	Medium
TL105CFW		6' w/ 5-15P Plug	120V	Medium
TL105CFWS		6' Direct Wire	120V	Medium
TL105CFPT		1' cord w/ 5-15P Plug and 1' cord w/ 5-15R Receptacle	277V	Mogul
TL105CF277		None	277V	Mogul

## MINI TEMPORARY CAGE LIGHTS



TLM

- Steel cage
- Medium base

### SPECIFICATIONS



MODEL #	DESCRIPTION	CORD	VOLTS
TLM	Mini Temporary Cage Lights	None	120V - 277V
TLMW		6' w/ 5-15P Plug	120V
TLMPT		6' Direct Wire	120V
TLMAGW		1' cord w/ 5-15P Plug and 1' cord w/ 5-15R Receptacle	277V

## DIRECT WIRE BOX MOUNTED TEMPORARY LIGHTS



TLCO

- Steel cage
- Medium bulb base
- Includes mounting plates for square and round boxes
- Direct wire

### SPECIFICATIONS



MODEL #	DESCRIPTION	BULB
TLCO	1,000 Lumen Box Mount Temp Cage Light	9W
TLMU	Box Mount Wall Sconce Temp Cage Light	----

# OVERHEAD JOBSITE LIGHTING

## REPLACEMENT BULBS.



LED100

- 6,500K color temperature
- LED bulbs. are IP64

### SPECIFICATIONS



MODEL #	DESCRIPTION	WATTS/ VOLTS	BULB LIFE	BULB BASE
C105651MED	6,400 Lumen, Fluorescent Bulb	105W/120V	8,000 hrs.	Medium
C105652MOG	6,400 Lumen, Fluorescent Bulb	105W/277V	8,000 hrs.	Mogul
LED036-E39	5,200 Lumen, LED Corncob Bulb	40W/120V-277V	50,000 hrs.	Medium
LED054-E39	7,800 Lumen, LED Corncob Bulb	60W/120V-277V	50,000 hrs.	Medium
LED080-E39	10,400 Lumen, LED Corncob Bulb	80W/120V-277V	50,000 hrs.	Mogul
LED100-E39	13,000 Lumen, LED Corncob Bulb	100W/120V-277V	50,000 hrs.	Mogul
LED125-E39	15,600 Lumen, LED Corncob Bulb	120W/120V-277V	50,000 hrs.	Mogul
LED150	19,500 Lumen, LED Corncob Bulb	120W/120V-277V	50,000 hrs.	Mogul
LED200	28,000 Lumen, LED Corncob Bulb	200W/120V-277V	50,000 hrs.	Mogul

## HANGING ACCESSORIES



SC5075HF



CPMH1



JC-100



JHK-32MAG



JHK-64



BRM200-HD

### SPECIFICATIONS

MODEL #	DESCRIPTION	FUNCTION
SC-5075HF	4" Square Swivel Fixture Hanger Ring, with Hands Free Door	Provides a threaded mounting point for the fixture hook and convenient hands free door for direct wire applications
SC-5075HFR	4" Round Swivel Fixture Hanger Ring, with Hands Free Door	Provides a threaded mounting point for the fixture hook and convenient hands free door for direct wire applications
SC-507511BHF	4-11/16" Round Swivel Fixture Hanger Ring, with Hands Free Door	Provides a threaded mounting point for the fixture hook and convenient hands free door for direct wire applications
CPMH1	Cage Light Fixture Hook with Threaded End	Pairs with swivel fixture hangers to provide a hanging surface for the light
JC-100	Zinc Fixture Support #12, 100'	Support light fixtures
JHK-32MAG	2" J Hook with 90 lb. Magnet	Supporting and managing string light or extension cord cables
JHK-64	2" J Hook with Mounting Hole	Supporting and managing string light or extension cord cables
JHK-32-AB	2" J Hook with Angled Bracket with Mounting Hole	Supporting and managing string light or extension cord cables
BRM200-HD	2" Bridal Rign with 90 lb. magnet	Supporting and managing string light or extension cord cables
58299040	14" Reusable Cable Ties, Black, 15 Pack	Manage cables and hang small fixtures
58298740	14" Reusable Cable Ties, Black, 100 Pack	Manage cables and hang small fixtures

BULBS. & ACCESSORIES

# OVERHEAD JOBSITE LIGHTING

## CAGE LIGHT ACCESSORIES



TLPS

### SPECIFICATIONS

MODEL #	DESCRIPTION
TLPS	Light Pollution Shield, 13" (Works with Medium Base Fixtures)
TLPS-L	Light Pollution Shield, 15" (Works with Mogul Base Fixtures)
TLGLK	Temp Light Lockable Acrylic Guard

# STRING LIGHTS

Southwire offers a full range of industrial string lights to help you light any area. Perfect for corridors and longer rooms, the majority of our string lights are available in 50 ft. & 100 ft. strands. We make sure to bring you the best in LED technology while also continuing to carry traditional E-base socket string lights. Not sure which one to choose? Provide us with your project dimensions and we'll recommend a product that works specifically for your jobsite.



# STRING LIGHTS

## LED STRING LIGHTS WITH UP-LIGHT

Shine light along hundreds of feet with ease, utilizing these convenient and easy-to-install integrated LED string lights. With no bulb to break or replace, these products are low profile and will provide service for years to come.

**50' AND 100'  
MODELS AVAILABLE**



**DAISY CHAIN UP TO 1,000'**

**NO BULBS -  
700 LUMEN DOWN LIGHT**



**IP65 HEAD**

**DURABLE CONSTRUCTION**

**100 LUMEN UPLIGHT ILLUMINATES  
CEILING TASKS LIKE CONDUIT AND  
STRUT WORK**



**UP-LIGHT STRING LIGHTS**



# STRING LIGHTS

## LED STRING LIGHT WITH REPLACEABLE HEADS

We know that string lights are often beat up, painted on, chemically damaged, or even have their cables cut. That's why we designed string lights with replaceable heads to help you keep the jobsite running smoothly — even when the unexpected happens.

**RATED FOR 50,000 HOURS  
LED LIFE (24/7 FOR 6 YEARS)**

**100 LUMEN UPLIGHT ILLUMINATES  
CEILING TASKS LIKE CONDUIT AND  
STRUT WORK**



**FEATURES AN E17 BASE**

**REPLACEABLE HEAD ALLOWS FOR  
CHANGE OUT IF DAMAGED, OR TO  
SALVAGE PARTS IF A CABLE IS CUT**



**REPLACEABLE HEAD**

# STRING LIGHTS

## LED STRING LIGHTS WITH UP-LIGHT



7164SW

- 5000K color temperature
- IP65 heads
- 800 lumens per head
- 100 lumen up-light, 700 lumen down light
- 5-15 plug and receptacle
- Mounting hole molded into top housing

### SPECIFICATIONS

MODEL #	DESCRIPTION	LENGTH	CORD TYPE	HEAD COUNT	LINKABLE UNITS
7164SW	50' - 14/3, 4,000 Lumen, LED String Light	50'	14/3 SJTW	5	1,000 ft.
7165SW	100' - 14/3, 8,000 Lumen, LED String Light	100'	14/3 SJTW	10	1,000 ft.



## LED STRING LIGHT - X UPLIGHT



71X5SW

- 2,200 lumens per head
- 120 VAC 50/60Hz
- 50ft & 100ft
- Diffused anti-glare lens
- Heavy-duty 16/3 cord
- 4-way mounting loop

### SPECIFICATIONS

MODEL #	DESCRIPTION	LENGTH	CORD TYPE	HEAD COUNT	LINKABLE UNITS
71X5SW	100' 22,000 Lumen LED String Light - X Uplight	100'	16/3 SJTW	10	5 ft.
71X4SW	50' 11,000 Lumen LED String Light - X Uplight	50'	16/3 SJTW	5	10 ft.
71X5SW520	100' 22,000 Lumen LED String Light - X Uplight L5-20 Twist Lock	100'	16/3 SJTW	10	5 ft.
71X4SW520	50' 11,000 Lumen LED String Light - X Uplight L5-20 Twist Lock	50'	16/3 SJTW	5	10 ft.

## LED STRING LIGHTS WITH REPLACEABLE LIGHT PANELS



97132

- 5600K color temperature
- Removable light panel with E17 base
- 900 lumens per head
- 1-15 Plug and receptacle with slide lock feature
- 50,000 hour fixture life
- Impact-resistant polycarbonate lens

### SPECIFICATIONS

MODEL #	DESCRIPTION	LENGTH	CORD TYPE	HEAD COUNT	LINKABLE UNITS
97120	20' - 18/2 STW, 900 Lumen LED String Light	20'	SJTW	1	N/A
97135	50' - 18/2 STW, 4,500 Lumen LED String Light	50'	SJTW	5	500 ft.
97132	100' - 18/2 STW, 9,000 Lumen LED String Light	100'	SJTW	10	500 ft.



LED STRING LIGHTS

# STRING LIGHTS

## 18/3 LED COB STRING LIGHTS



- Each LED lead delivers 1,200 lumens
- Input voltage: AC 120V
- Includes hanging clip for quick hanging
- 18/3 SJTW power supply cord
- NEMA 5-15R daisy chain receptacle

### SPECIFICATIONS

MODEL #	DESCRIPTION	LENGTH	CORD TYPE	HEAD COUNT	LINKABLE UNITS
7174SW	50' 8,000 Lumen LED String Light	50'	SJTW	5	400 ft.
7175SW	100' 16,000 Lumen LED String Light	100'	SJTW	10	400 ft.

## 16/3 LED STRING LIGHTS



- Each LED lead delivers 1,200 lumens
- Input voltage: AC 120V
- Includes hanging clip for quick hanging
- 18/3 SJTW power supply cord
- NEMA 5-15R daisy chain receptacle

### SPECIFICATIONS

MODEL #	DESCRIPTION	LENGTH	CORD TYPE	HEAD COUNT	LINKABLE UNITS
7184SW	50' 12,500 Lumen LED String Light	50'	SJTW	5	400 ft.
7185SW	100' 12,000 Lumen LED String Light	100'	SJTW	10	400 ft.

## STANDARD PLASTIC STRING LIGHTS



7145SW

- Medium base socket
- Integrated plug
- Sockets rated to 150W
- NEC compliant
- Meets OSHA requirements
- Integrated daisy chain socket (12/3 & 14/3 models only)

### SPECIFICATIONS



MODEL #	DESCRIPTION	JACKET	CORD TYPE	CAGE TYPE	LENGTH	PLUG & RECEPTACLE	SOCKET COUNT	
7145SW	100', 14/2 SJTW String Light, Plastic Cages	SJTW	14/2	Plastic	100 ft.	1-15 Only	10	
7155SW	100' 14/3 SJTW String Light, Plastic Cages		14/3	Plastic	100 ft.	5-15	10	
7548SW	50' 12/3 SJTW String Light, Plastic Cages		12/3	Pre-Assembled Plastic	Plastic	50 ft.	5-15	5
7549SW	100' 12/3 SJTW String Light, Plastic Cages				Plastic	100 ft.	5-15	10
96132	100' 12/3 SJTW String Light, Plastic Cages				100 ft.	5-15	10	
94132	100' 14/2 STW String Light, Plastic Cages				STW	14/2	Pre-Assembled Plastic	100 ft.
7146SW	100' 12/2 STW String Light, Plastic Cages		12/2	Plastic		100 ft.	1-15 Only	10
95135	50' 12/3 STW String Light, Plastic Cages		12/3	Pre-Assembled Plastic		50 ft.	5-15	5
95132	100' 12/3 STW String Light, Plastic Cages		12/3	Pre-Assembled Plastic		100 ft.	5-15	10

STANDARD STRING LIGHTS

# STRING LIGHTS

## STANDARD METAL STRING LIGHTS



7539SW

- Medium base socket
- Integrated plug and receptacle
- Sockets rated to 150W
- NEC compliant
- Meets OSHA requirements



### SPECIFICATIONS

MODEL #	DESCRIPTION	JACKET	CORD TYPE	CAGE TYPE	LENGTH	PLUG & RECEPTACLE	SOCKET COUNT
7538SW	50' 12/3 SJTW String Light, Metal Cages	SJTW	12/3	Metal	50 ft.	5-15	5
7539SW	100' 12/3 SJTW String Light, Metal Cages			Metal	100 ft.	5-15	10
7599SW	100' 12/3 STW String Light, Metal Cages	STW		Metal	100 ft.	5-15	10
95137	50' 12/3 STW String Light, Metal Cages			Pre-Assembled Metal	50 ft.	5-15	5
95133	100' 12/3 STW String Light, Metal Cages			Pre-Assembled Plastic	100 ft.	5-15	10

## STRING LIGHTS WITH LED BULBS.



121050

- Medium base socket
- Integrated plug
- Rough service LED bulb
- 5000K Color temperature
- NEC compliant
- Meets OSHA requirements



### SPECIFICATIONS

MODEL #	BULB LUMENS	DESCRIPTION	JACKET	CORD TYPE	CAGE TYPE	LENGTH	PLUG & RECEPTACLE	SOCKET COUNT
SLP142J100K80	800	100' 14/2 SJTW String Light with 800 Lumen Bulb, Plastic Cages	SJTW	14/2	Plastic	100 ft.	1-15 Plug Only	10
SLP143J100K80	800	100' 14/3 SJTW String Light with 800 Lumen Bulb, Plastic Cages		14/3	Plastic	100 ft.	5-15	10
1111000	1,500	100' 14/2 SJTW String Light with 1,500 Lumen Bulb, Plastic Cages		14/2	Plastic	100 ft.	1-15 Plug Only	10
1311000	1,500	100' 14/3 SJTW String Light with 1,500 Lumen Bulb, Plastic Cages		14/3	Plastic	100 ft.	5-15	10
121050	1,500	50' 12/3 STW String Light with 1,500 Lumen Bulb, Plastic Cages	STW	12/3	Metal	50 ft.	5-15	5
1211000	1,500	100' 12/3 STW String Light with 1,500 Lumen Bulb, Plastic Cages			Metal	100 ft.	5-15	10

LOCKING STRING LIGHTS

# STRING LIGHTS

## STANDARD TWIST-LOCK STRING LIGHTS



SLP123J100L

- Medium base socket
- Integrated plug and receptacle
- L5-20 plug and receptacle
- Sockets rated to 150W

### SPECIFICATIONS



MODEL #	DESCRIPTION	JACKET	CORD TYPE	CAGE TYPE	LENGTH	PLUG & RECEPTACLE	SOCKET COUNT
SLP123J50L	50' 12/3 SJTW Locking String Light, Plastic Cages	SJTW	12/3	Plastic	50 ft.	L5-20	5
SLP123J100L	100' 12/3 SJTW Locking String Light, Plastic Cages			Plastic	100 ft.	L5-20	10
95125	50' 12/3 SJTW Locking String Light, Plastic Cages	STW		Pre-Assembled Plastic	50 ft.	L5-20	5
95122	100' 12/3 STW Locking String Lights, Plastic Cages			Pre-Assembled Plastic	100 ft.	L5-20	10
95127	50' 12/3 STW Locking String Lights, Metal Cages			Pre-Assembled Plastic	50 ft.	L5-20	5
95123	100' 12/3 STW Locking String Lights, Metal Cages			Pre-Assembled Plastic	100 ft.	L5-20	10

\*UL Listed only.

## STRING LIGHTS REPLACEMENT PARTS



111923

### SPECIFICATIONS

MODEL #	DESCRIPTION	WORKS WITH
72002000	Metal Replacement Cage	All standard string light models
73010000	Plastic Replacement Cage	All standard string light models
9700	Replacement Magnetic Yolk	91135, 91120
9709	E17 Replacement Light Panel	97120, 97135, 97132
9711	E26 Replacement Light Panel	97132, 97135
105WCFL	Compact Fluorescent, 105W	All standard string light models
23WCFL	Compact Fluorescent, 23W	All standard string light models
111919	800 Lumen LED Medium Base Bulb	All standard string light models
111923	1,500 Lumen LED Medium Base Bulb	All standard string light models

PARTS & ACCESSORIES

# CART LIGHTS

---

Southwire offers many high lumen cart lights to make sure any job can be well lit while still giving you the option to move lights around the jobsite easily and effortlessly. Whether you need 11,000 lumens or 44,000 lumens, Southwire has you covered. We also understand that some jobs are still using halogen cart lights so we have made sure to continue to bring you a great halogen cart light option that has stood the test of time.



# CART LIGHTS

## 7000 SERIES LED CART LIGHT



7322

- 125V
- 12' 18/3 SJTW power cord - 5-15
- Self-breaking wench - 7322

- Adjustable head with protective wire cages
- Steel cart base
- Wet locations



### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	MAST HEIGHT	HANDLE/MAST STYLE	HEAD COUNT	TOTAL WATTS	AMPS
7309	22,000 Lumen, Single Head, 2 Stage Cart Light	22,000	5 ft. - 10 ft.	2 Stage Mast	1	200W	1.7A
7322	44,000 Lumen, Dual Head, 2 Stage Winch Cart Light	44,000	5.5 ft. - 12 ft.	2 Stage with 600 lbs. Winch	2	400W	2.14A

### ACCESSORIES

7300HA	Replacement Head for 7309	22,000	---	---	---	---	---
7300DHA	Replacement Head for 7322	44,000	---	---	---	---	---

## 9000 SERIES LED CART LIGHT



9322

- 125V
- 12' 18/3 SJTW power cord - 5-15

- Adjustable head with protective wire cages
- Steel cart base
- Wet locations



### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	MAST HEIGHT	HANDLE/MAST STYLE	HEAD COUNT	TOTAL WATTS	AMPS
9842	11,000 Lumen, Twin Head, 2 Stage Cart Light	11,000	5 ft. - 10 ft.	2 Stage Mast	2	100W	0.8A
9322	44,000 Lumen, Quad Head, 2 Stage Winch Cart Light	22,000	5.5 ft. - 12 ft.	2 Stage Mast with 600 lbs. Winch	4	200W	1.6A

### ACCESSORIES

9800DHA	Replacement Head for 9842	11,000	---	---	---	---	---
9900DHA	Replacement Head for 9322	22,000	---	---	---	---	---

WIRE CAGE CART LIGHTS

# WORK LIGHTS

---

From LED to halogen, rechargeable to corded, we've got a work light for almost any situation. Many of our work lights carry high IP ratings, with weather-resistant ratings, and some even being submersible in water. If durability and power are what you're looking for in a work light then Southwire will be able to satisfy your needs.





# WORK LIGHTS

## AL SERIES RECHARGEABLE AND CORDED WORK LIGHTS

For the serious tradesman, Southwire's AL series work light is packed with features and is built to last.



**CORDED 6,000 AND 10,000 LUMEN MODELS  
RECHARGEABLE 2,000 AND 6,000 LUMEN MODELS**




**APP ENABLED, CONTROL MULTIPLE LIGHTS  
FROM THE SAME APP (AVAILABLE ON THE 6,000  
AND 10,000 LUMEN MODELS)**

**USB OUTPUT  
FOR CHARGING**



**DIMMING CONTROLS &  
BATTERY LEVEL INDICATOR**

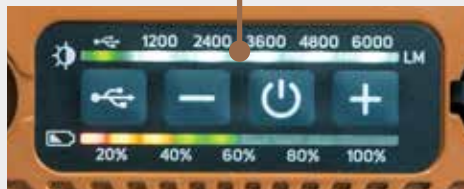

**TILTING STAND**



**DURABLE IP67, SUBMERSIBLE  
IN WATER & DROP TESTED FROM  
1 METER**

**AL SERIES WORK LIGHTS**

# WORK LIGHTS

## SLIM SERIES LED WORK LIGHT



411050



411350

- Aluminum body
- IP65, indoor or outdoor use
- Operating temp: -40°F to 122°F
- 5000K LED with 50,000 hrs. life
- 120V, 5' - 18/3 SJTW cord

### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	WATTS	STAND
411015	1,500 Lumen LED Slim Work Light	1,500	15W	Floor Stand
411215	1,500 Lumen LED Slim Work Light w/ Tripod	1,500	15W	Tripod
411315	3,000 Lumen LED Twin Head Slim Light w/ Tripod	1,500 x2	30W	Tripod
411030	3,000 Lumen LED Slim Work Light	3,000	30W	Floor Stand
411430	3,000 Lumen LED Slim Work Light w/ Magnetic Base	3,000	30W	Magnetic Disc Base
411230	3,000 Lumen LED Slim Work Light w/ Tripod	3,000	30W	Tripod
411330	6,000 Lumen LED Twin Head Slim Light w/ Tripod	3,000 x2	60W	Tripod
411050	5,000 Lumen LED Slim Work Light	5,000	50W	Floor Stand
411450	5,000 Lumen LED Slim Work Light w/ Magnetic Base	5,000	50W	Magnetic Disc Base
411250	5,000 Lumen LED Slim Work Light w/ Tripod	5,000	50W	Tripod
411350	10,000 Lumen LED Twin Head Slim Light w/ Tripod	5,000 x2	100W	Tripod



## AL SERIES HEAVY DUTY WORK LIGHT



AL100CSW

- IP67 - submersible in water
- Impact-resistant die-cast housing, drop tested to 1M
- USB power outlet for charging other devices
- 3-year warranty
- Dimmable
- Bluetooth® control via app available in Apple and Android store
- Dual power system: can run on charge or while plugged in

### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	WATTS	STAND
AL100CSW	10,000 Lumen LED Work Light	10,000	100W	Magnetic Swivel Stand
AL60CSW	6,000 Lumen LED Work Light	6000	60W	Magnetic Swivel Stand



## RECHARGEABLE AL SERIES LED WORK LIGHTS



AL60RSW

- IP67 - submersible in water
- Impact-resistant die-cast housing
- Drop tested to 1M
- USB Power outlet for charging other devices
- 3-year warranty
- Dimming capability
- Bluetooth® control via app available in Apple and Android store
- Dual-power system

### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	RUN TIME	WATTS	RECHARGE TIME	STAND
AL60RSW	6,000 Lumen LED Rechargeable Work Light	6,000	1 hrs. - 6 hrs.	60W	8 hrs.	Swivel Stand



CORDED WORK LIGHTS

# WORK LIGHTS

## 9000 SERIES HEAVY DUTY LED WORK LIGHT




9125

- 50,000 hour rated LED
- 5000K color temperature
- 120V
- All-steel stand and tripod
- Rated for wet locations
- Impact-resistant poly carbonate lens
- Replacement lenses available to cover paint and chemical over spray



### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	HEAD COUNT	WATTS	STAND
9055	5,500 Lumen LED Roll Cage Work Light	5,500	1	50W	Roll Cage
9125	5,500 Lumen LED Floor Stand Work Light	5,500	1	50W	Floor Stand & Magnet
9750	5,500 Lumen LED Single Head Work Light on Tripod	5,500	1	50W	19" DIA - 2 Stage Tripod

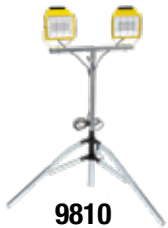

9810

## PROLIGHT™ XLE SERIES LED HEAVY DUTY WORK LIGHT



111500

- IP65 indoor or outdoor use
- Operating temp: -30°F to 120°F
- 5000K LED with 50,000 hrs. life
- Aluminum body, tempered glass, and protective cage
- 120V, 5' - 18/3 SJTW cord



### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	WATTS	STAND
111500	6,500 Lumen LED PROLIGHT™ Work Light w/ Floor Stand	6,500	50W	Floor Stand
111505	6,500 Lumen LED PROLIGHT™ Work Light w/ Tripod	6,500	50W	Tripod
111507	6,500 Lumen LED PROLIGHT™ Work Light w/ Magnet	6,500	50W	Magnet
111000	13,000 Lumen LED PROLIGHT™ Twin Head Work Light	6,500 x2	100W	Dual Head w/ Tripod
111005	13,000 Lumen LED PROLIGHT™ Twin Head Work Light w/ Tripod	6,500 x2	100W	Dual Head w/ Tripod

## RATCHETING LED WORK LIGHTS



CSW10X1

- Multi-position ratcheting floor stand
- 360° rotating head
- On/Off switch
- 18/3 SJTW cord
- 5000K color temperature

### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	HEIGHT	WIDTH	LENGTH	WEIGHT
CSW1X1	1500 Lumen Ratcheting LED Work Light	1,500	26"	7"	24.5"	2.7 lbs.
CSW3X1	3000 Lumen Ratcheting LED Work Light	3,000	26"	7"	24.5"	2.7 lbs.
CSW5X1	5000 Lumen Ratcheting LED Work Light	5,000	28"	8"	26.5"	3.7 lbs.
CSW10X1	10000 Lumen Ratcheting LED Work Light	10,000	31.5"	9"	31.5"	4.7 lbs.

CORDED WORK LIGHTS

# WORK LIGHTS

## WING LIGHTS



9220


- Rotating panel design allows for 180° to 360° illumination
- 5000K color temperature
- 120V
- All-steel stand and tripod
- Suitable for wet locations
- Impact-resistant polycarbonate lens
- Replacement lenses available to cover paint and chemical over spray

### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	WATTS	STAND
9220	8,000 Lumen LED Wing Style Work Light on Tripod	8,000	80W	H-Stand
9270	8,000 Lumen LED Wing Style Work Light on Tripod			Tripod



## DUAL HEAD LED WORK LIGHTS

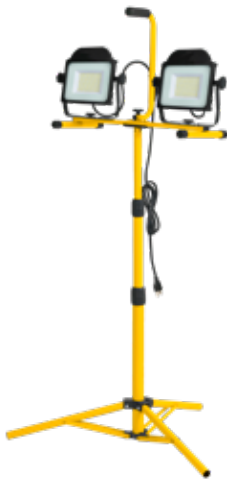

CSW10X2

- Includes: 2-step tripod stand
- Quick-release dual head base
- On/Off switch
- 18/3 SJTW cord
- 5000K color temperature
- CSW3X2: Each head delivers 3000 lumens
- CSW5X2: Each head delivers 5000 lumens
- CSW10X2: Each head delivers 10000 lumens

### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	HEIGHT	WIDTH	LENGTH	WEIGHT
CSW3X2	6000 Lumen Dual Head Work Light with Tripod	6,000	48.5"	16"	21"	9.4 lbs.
CSW5X2	10000 Lumen Dual Head Work Light with Tripod	10,000	62.5"	16"	24"	12.4 lbs.
CSW10X2	20000 Lumen Dual Head Work Light with Tripod	20,000	68"	16"	24"	14.9 lbs.

## HALOGEN WORK LIGHTS



L20

### SPECIFICATIONS

MODEL #	DESCRIPTION	WATTS	HEAD COUNT	STAND
L878	Halogen Work Light with 4-in-1 Mounting Kit	250W	1	4-in-1, Curved Tube Stand, clamp, ground stake, hanging hook
L860	Halogen Work Light	250W	1	Curved Tube Stand
L20	Halogen Work Light with Plastic Handle	500W	1	Curved Tube Stand
L33	Halogen Work Light with Metal Handle	500W	1	Curved Tube Stand
5125ITL	Halogen Work Light with Twist Lock Plug	500W	1	Curved Tube Stand
L10SLED	Halogen Work Light with Tripod and Detachable H-Stand	500W	1	Tripod and Detachable H-Stand
L13	Halogen Twin Head Work Light with Tripod	1,000W	2	Tripod
L14SLED	Halogen Twin Head Work Light with Tripod and Detachable Sled	1,000W	2	Tripod and Detachable Sled

CORDED WORK LIGHTS

# WORK LIGHTS

## TRIPODS



311001

### SPECIFICATIONS



MODEL #	DESCRIPTION	MAX HEIGHT	WEIGHT	WORKS WITH
311001	Standard Tripod	5'	7.5 lbs.	411215, 511510, 514124, 514125, 516001, 516002, 516003, 516004
311006	Medium Duty Tripod	5'	8.5 lbs.	411315, 411230, 411330, 411250, 411350, 111505, 515100, 515103, 515104
311007	Heavy Duty Tripod	6'	9.5 lbs.	111005, 111508, 111509

## HALOGEN REPLACEMENT BULBS



L23

### SPECIFICATIONS



MODEL #	DESCRIPTION	WATTS	BULB QUANTITY
5911	T3 Halogen Bulb	150W	1
L21	T3 Halogen Bulb in Plastic Storage Case, 6 Pack	250W	6
L96	T3 Halogen Bulb	250W	1
L22	T3 Halogen Bulb in Plastic Storage Case, 6 Pack	300W	6
L12500W	T3 Halogen Bulb in Plastic Storage Case, 3 Pack	500W	3
L16	T3 Halogen Bulb	500W	1
L23	T3 Rough Service Halogen Bulb in Plastic Storage Case, 6 Pack	500W	6
78805000SW	T3 Halogen Bulb, 50 Pack	500W	50
L15	T3 Halogen Bulb in Plastic Storage Case, 6 Pack	600W	6

HALOGEN WORK LIGHTS

# PERSONAL LIGHTING

---

Southwire offers a unique range of personal and handheld lighting from headlamps to rechargeable handheld lights. The entire range is loaded with unique features that will bring you ease in any situation you encounter. When buying a Southwire Personal Light, make sure to review our IP ratings and battery runtimes, as we've built them to meet the harsh demands of the jobsite.



# PERSONAL LIGHTING

## ALKALINE BATTERY HEAD LAMP



HL1030SW

- Foam forehead pad
- Adjustable elastic head band
- Smooth dimming
- Hinged aimable head
- 2 x AAA batteries included

### SPECIFICATIONS

MODEL #	DESCRIPTION	SPOT LIGHT LUMENS	FLOOD LIGHT LUMENS	RUN TIME	BATTERIES INCLUDED
HL1030SW	300 Lumen LED Adjustable Headlamp with (2x) AAA	120	300 - High 30 - Low	Up to 30 hrs.	2 x AAA Batteries

## RECHARGEABLE HEAD LAMPS



HL12RSW

- Detachable magnetic light head
- Constant current - maintains light level throughout the life of the charge
- IP65 - weatherproof
- 3-year warranty
- Lithium ion battery
- HL25RSW has a hands free on/off sensor and down light for near field tasks like reading
- Includes two hard hat clips and charger

### SPECIFICATIONS



HL25RSW

MODEL #	DESCRIPTION	DOWN LIGHT LUMENS	SPOT LIGHT LUMENS	FLOOD LIGHT LUMENS	RUN TIME	RECHARGE TIME
HL12RSW	120 Lumen Rechargeable LED Head Lamp	N/A	N/A	120 - High 60 - Low	Up to 5 hrs.	2-3 hrs.
HL25RSW	250 Lumen Rechargeable LED Head Lamp	120 - High, 60 - Low	150	250 - High 75 - Low	Up to 8 hrs.	2-3 hrs.

## SL SERIES RECHARGEABLE HAND HELD LIGHTS



SL20RSW  
SL50RSW

- Magnetic base
- Hanging hook
- Articulating arm
- Spot light tip
- 1M drop test
- Includes carrying case
- Constant current - maintains light level throughout the life of the charge
- 3-year warranty
- Lithium ion battery

### SPECIFICATIONS

MODEL #	DESCRIPTION	SPOT LIGHT LUMENS	FLOOD LIGHT LUMENS	RUN TIME	CHARGER INCLUDED
SL20RSW	200 Lumen Rechargeable Folding LED Handheld Light	100	200 - High 50 - Low	Up to 10 hrs.	Yes
SL50RSW	500 Lumen Rechargeable Folding LED Handheld Light	100	500 - High 100 - Low	Up to 12.5 hrs.	Yes

HEAD LAMPS & HAND HELDS

# PERSONAL LIGHTING

## YELLOW JACKET® H SERIES RECHARGEABLE HAND HELD LIGHTS



HHL1030R HHL1060R

- Magnetic swivel base
- Smooth dimming
- Hanging hook
- 6000K color temperature
- Lithium ion battery
- Spot light on tip (HHL1040R and HHL1060R)

### SPECIFICATIONS

MODEL #	DESCRIPTION	SPOT LIGHT LUMENS	FLOOD LIGHT LUMENS	RUN TIME	CHARGER INCLUDED
HHL1030R	200 Lumen Yellow Jacket Rechargeable LED Pocket Light	NA	300 - High 30 - Low	Up to 10 hrs.	Yes
HHL1040R	400 Lumen Yellow Jacket Rechargeable LED Hand Held Adjustable Light	80	400 - High 40 - Low	Up to 10 hrs.	Yes
HHL1060R	600 Lumen Yellow Jacket Rechargeable LED Hand Held Adjustable Light	150	600 - High 60 - Low	Up to 15 hrs.	Yes

## WOODS® ALKALINE BATTERY HAND HELD LIGHT



TLB20020

- Magnetic swivel base
- Spot light in end of light
- Swivel hanging hook

### SPECIFICATIONS

MODEL #	DESCRIPTION	LUMENS	BATTERY TYPE
TLB20020	200 Lumen Handheld Task Light, w/ 3x AA Batteries	200	3x AA Batteries

HAND HELD LIGHTS



# CLAMP & TROUBLE LIGHTS

Southwire's line of trouble lights and clamp lights are extensive to fit any need you might have. These trouble lights come in medium or heavy-duty styles, each with multiple variants to fit your specific needs, while Southwire clamp lights come in a wide range of wattage and reflector sizes.



# CLAMP & TROUBLE LIGHTS

## MEDIUM DUTY TROUBLE LIGHTS



692

### SPECIFICATIONS



MODEL #	DESCRIPTION	CORD LENGTH	CORD	JACKET	OUTLET	GUARD
200	Medium Duty 15' Plastic Trouble Light, 18/2	15'	18/2	SJTW	No	Plastic
201	Medium Duty 25' Plastic Trouble Light, 18/2	25'	18/2		No	Plastic
681	Medium Duty 25' Metal Trouble Light, 18/3 w/ Outlet	25'	18/3		Yes	Metal
682	Medium Duty 50' Metal Trouble Light, 18/3 w/ Outlet	50'	18/3		Yes	Metal
691	Medium Duty 50' Metal Trouble Light, 16/3 w/ Outlet	25'	16/3		Yes	Metal
692	Medium Duty 50' Metal Trouble Light, 16/3 w/ Outlet	50'	16/3		Yes	Metal
48000	Metal Cord Reel, 40' Metal Trouble Light w/ Outlet	40'	16/3		Yes	Metal

## HEAVY DUTY TROUBLE LIGHTS



58588802SW

- Durable oil-resistant cord jacket
- Elastomer cord jacket allows for maximum flexibility

### SPECIFICATIONS



MODEL #	DESCRIPTION	CORD LENGTH	CORD	JACKET	OUTLET	GUARD
56578802SW	Heavy Duty Trouble Light, 16/3, 25' SJEOW, Metal Guard, w/ Outlet	25'	16/3	SJEOW	Yes	Metal
56588802SW	Heavy Duty Trouble Light, 16/3, 50' SJEOW, Metal Guard, w/ Outlet	50'			Yes	Metal
58578802SW	Heavy Duty Trouble Light, 14/3, 25' SJEOW, Metal Guard, w/ Outlet	25'	14/3		Yes	Metal
58588802SW	Heavy Duty Trouble Light, 14/3, 50' SJEOW, Metal Guard, w/ Outlet	50'			Yes	Metal

MEDIUM & HEAVY DUTY

# CLAMP & TROUBLE LIGHTS

## STEEL CLAMP LIGHTS



160

- Non-marring clamp grip
- Built-in hook
- 18/2 cord
- Porcelain socket
- Steel clamp
- Push-through switch

### SPECIFICATIONS



MODEL #	DESCRIPTION	WATTS	CORD	REFLECTOR DIA	BULB PROTECTOR
160	60W Clamp Light with 5.5" Reflector	60W	6' SJTW	5.5"	No
324	125W Clamp Light with Wire Reflector	125W	6' SJTW	Wire	No
328	150W Clamp Light with None Reflector	150W	6' SJTW	None	No
151	150W Clamp Light with 8.5" Reflector	150W	6' SJTW	8.5"	No
2839	150W Clamp Light Socket with No Reflector	150W	12' SJTW	8.5"	No
162	150W Clamp Light with 10" Reflector	150W	6' SJTW	10"	No
165	250W Clamp Light with 10.5" Reflector	250W	6' SJTW	10.5"	Yes
166	300W Clamp Light with 10" Reflector	300W	6' SJTW	10"	Yes
167	300W Clamp Light with 10.5" Reflector	300W	8' SJTW	10.5"	Yes

## LED CLAMP LIGHT



CL20600YJ

- Non-marring clamp grip
- 18/2 cord

### SPECIFICATIONS



MODEL #	DESCRIPTION	CORD
CL20600YJ	600 Lumen LED Clamp Light	6' SJTW

CLAMP LIGHTS

# INSTALLED LIGHTS

Southwire's installed lights cover a wide range of uses from durable steel-armed dock lights to powerful security and dusk to dawn lights, to weathertight utility lights. We have made sure to provide you with high-output LED options as well as traditional bulb products.



# INSTALLED LIGHTS

## DOCK LIGHTS



111510

- 40" Reach
- IP65 - weatherproof (111510 and 111515)

- Durable steel arm that prevent sagging
- Integrated power cord with plug

### SPECIFICATIONS



MODEL #	DESCRIPTION	LUMENS	WATT	LIGHT SOURCE	LIGHT COLOR TEMPERATURE	BULB LIFE	FEATURES	CERTIFICATION
111510	LED Dock Light	1,700	20W	Integrated LED	5000K	50,000 hrs.	IP65	cUL
111515	Replacement LED Dock Light Head							

SECURITY LIGHTS

# HAZARDOUS LOCATION LIGHTING

Southwire carries a selection of hazardous location rated drop and inspection lights that allow you to safely light a hazardous location.



# HAZARDOUS LOCATION

## HAZARDOUS LOCATION LED LIGHTS



514009

- Lithium ion battery
- For use in hazardous areas
- Impact-resistant construction

### SPECIFICATIONS



MODEL #	DESCRIPTION	LUMENS	RUN TIME	BATTERY TYPE	IP RATING	FEATURE
514007	125 Lumen Intrinsically Safe LED Flashlight	125 LM - High 55 LM - Low	42.5 Hrs. - High 80 Hrs. - Low	x3 C	IP67	Waterproof
514008	160 Lumen Intrinsically Safe LED Flashlight	160 LM - High 65 LM - Low	6 Hrs. - High 13 Hrs. - Low	x4 AA	IP67	Waterproof
514009	270 Lumen Intrinsically Safe Right Angle LED Flashlight	270 LM - High 135 LM - Low	6.5 Hrs. - High 13 Hrs. - Low	x4 AA	IP54	Waterproof
514012	200 Lumen Intrinsically Safe LED Head Lamp	200 LM - High 100 LM - Low	2.5 Hrs. - High 4.5 Hrs. - Low	x3 AAA	IP67	Waterproof

DROP LIGHTS



**Southwire™**

# TEMPORARY LIGHTING SOLUTIONS CATALOG

**get social with us:**



[/SOUTHWIRETOOLS](#)



[/SOUTHWIRE-COMPANY](#)



[@SOUTHWIRETOOLS](#)



[@SOUTHWIRE](#)



SCAN TO LEARN MORE

[WWW.SOUTHWIRE.COM](http://WWW.SOUTHWIRE.COM) | 1-855-SWTTOOLS

All Trademarks or Registered Trademarks (TM/®) are owned or licensed by Southwire Company.  
Any other TM/®- Trademark or Registered Trademark of Southwire Company.