



Southwire®

SPECIAL EDITION

PRODUCT CATALOG



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

SOUTHWIRE.COM



Southwire®

— PROUDLY SUPPORTING —
**OUR NATION'S
HEROES**

Southwire is proud to announce our new partnership with Wounded Warrior Project®.

This incredibly special partnership represents our continued focus to support our veterans, our communities, and the markets we serve.



PROUDLY SUPPORTING
**OUR NATION'S
HEROES**



HAND TOOLS

HAND TOOLS

Made from American forged steel, these tools are built to withstand jobsite wear and tear. Assembled with hot rivet technology, these pliers are designed to be the livelihood of every professional. The wire strippers are also fully equipped to handle day-to-day demands. Our tradesmen and women meet every job with heart and pride. Their tools should, too.

9" TERMINAL CRIMPER/ CUTTER

- Made from American forged steel for durability
- Crimps insulated and non-insulated terminals & connectors
- Specially hardened wire cutter in nose
- Tapered nose for working in confined spaces
- Double-dipped grip for comfortable fit

9" HIGH-LEVERAGE SIDE CUTTING PLIERS

- Made from American forged steel for durability
- Hot riveted pivot joint for smooth, sturdy action
- High-leverage design provides maximum cutting power
- Induction hardened cutting blades ensure efficient and lasting cutting surfaces for hard and soft wire
- Features a crimper, fish tape puller, and reaming head for added versatility
- Double-dipped grip for comfortable fit

8" ANGLED HEAD HIGH-LEVERAGE DIAGONAL CUTTING PLIERS

- Made from American forged steel for durability
- Hot riveted pivot joint for smooth, sturdy action
- Effectively cuts most hardened wire, ACSR, bolts, screws, and nails
- High-leverage design provides maximum cutting power
- Angled head allows for easy work in confined spaces
- Double-dipped grip for comfortable fit

9" CABLE CUTTING PLIER

- Made from American forged steel for durability
- Cuts up to 4/0 AWG aluminum, 2/0 AWG copper, and 100-pair 24 AWG communications cable
- Induction hardened blades for maximum durability
- Double-dipped grip for comfortable fit



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

HAND TOOLS

10-20 AWG SOL & 12-22 AWG STR COMPACT HANDLES WIRE STRIPPER/CUTTER


- Made from durable heat-treated steel for longer life
- Strips and cuts up to 10-20 AWG solid & 12-22 AWG stranded wire
- Double-dipped grip for comfortable fit
- Serrated nose holds cable for easy twisting & pulling
- Spring-loaded for self-opening action
- Not intended for cutting bolts or steel wire

10-18 AWG SOL & 12-20 AWG STR ERGO HANDLES WIRE STRIPPER/CUTTER

- Made from durable heat-treated steel for longer life
- Strips and cuts 10-18 AWG solid & 12-20 AWG stranded wire
- Double-dipped grip for comfortable fit
- Shears 8-32 & 6-32 screws
- Precision, shear-type cutting blades for easier cutting
- Not designed for cutting steel wire

ROMEX™ BRAND BOX JAW™ WIRE STRIPPER

- Patented design allows for straight on stripping in boxes
- Precision ground blades strip 12/2 to 14/2 Romex™ Brand wire
- Double dipped comfort grip handles
- 6-32 & 8-32 Screw shearing holes
- Spring loaded handles
- Lock keeps blades closed for storage

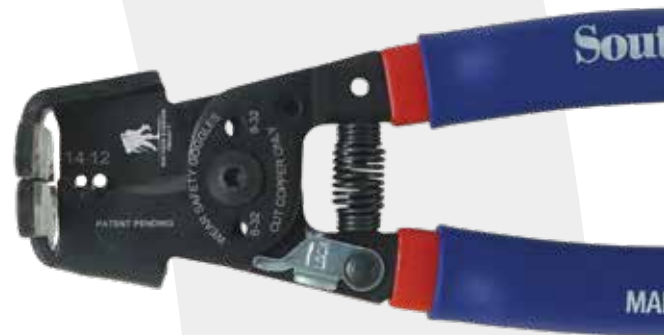

MODEL #	MATERIAL #	UPC	DESCRIPTION
TCC9D-WW	67038640	032886997570	9" Terminal Crimper & Cutter, Dip Grip, Wounded Warrior
SCP9TPCD-WW	67038040	032886997532	9" Side Cutting Plier, Fish Tape Puller, Crimper, Dip Grip, Wounded Warrior
DCPA8D-WW	67038340	032886997556	8" Diagonal Cutting Pliers, Angled Head, Dip Grip, Wounded Warrior
CCP9D-WW	67038940	032886997563	9" Cable Cutter, High-Leverage, Dip Grip, Wounded Warrior
S1020SOL-WW	67039240	032886997594	10-20 AWG SOL & 12-22 AWG STR Compact Wire Stripper, Wounded Warrior
S1018SOL-WW	67039540	032886997600	10-18 AWG SOL & 12-20 AWG STR Ergonomic Wire Stripper, Wounded Warrior
SNM1214HH-WW	67039840	032886718656	12/2 & 14/2 Romex™ Brand Box Jaw Wire Stripper, Wounded Warrior

APPRENTICE KIT

6 PIECE APPRENTICE KIT

9" TERMINAL CRIMPER/ CUTTER

- Crimps insulated and non-insulated terminals & connectors
- Specially hardened wire cutter in nose
- Tapered nose for working in confined spaces

9" HIGH-LEVERAGE SIDE CUTTING PLIERS

- Hot riveted pivot joint for smooth, sturdy action
- High-leverage design provides maximum cutting power
- Induction hardened cutting blades ensure efficient and lasting cutting surfaces for hard and soft wire
- Features a crimper, fish tape puller, and reaming head for added versatility

8" ANGLED HEAD HIGH-LEVERAGE DIAGONAL CUTTING PLIERS

- Hot riveted pivot joint for smooth, sturdy action
- Effectively cuts most hardened wire, ACSR, bolts, screws, and nails
- High-leverage design provides maximum cutting power
- Angled head allows for easy work in confined spaces

10-20 AWG SOL & 12-22 AWG STR COMPACT HANDLES WIRE STRIPPER/CUTTER

- Strips and cuts up to 10-20 AWG solid & 12-22 AWG stranded wire
- Serrated nose holds cable for easy twisting & pulling
- Spring-loaded for self-opening action
- Not intended for cutting bolts or steel wire

#2 PHILLIPS HEAD SCREWDRIVER

- 22% Larger cushion grip handle provides ultimate comfort and maximum torque
- Corrosion resistant shank
- Tether hole for tether or lanyard attachment

1/4" CABINET TIP SCREWDRIVER


- 22% Larger cushion grip handle provides ultimate comfort and maximum torque
- Corrosion resistant shank
- Tether hole for tether or lanyard attachment



MODEL #	MATERIAL #	UPC	DESCRIPTION	MASTER PACK QTY.
6PUSAKIT-WW	67035140	032886301193	6 Piece Apprentice Kit	1

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

INDUSTRIAL GRADE. AMERICAN MADE.

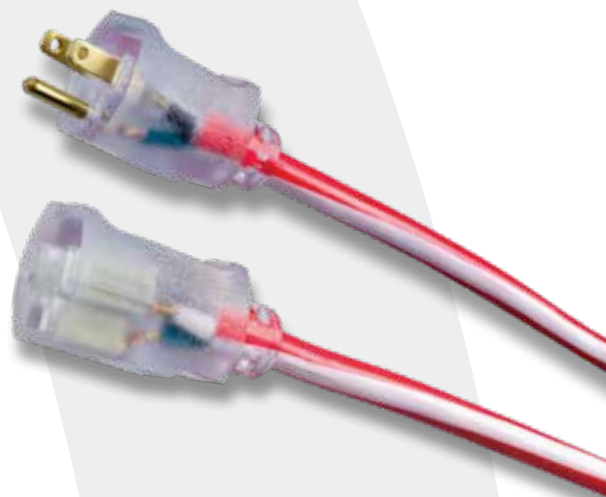

MODEL #	UPC	DESCRIPTION	LENGTH	WEIGHT
2547SWUSA1	029892052034	12/3 SJTW Lighted End 25'	25'	3.403 lbs.
2548SWUSA1	029892051587	12/3 SJTW Lighted End 50'	50'	6.535 lbs.
2549SWUSA1	029892051570	12/3 SJTW Lighted End 100'	100'	12.727 lbs.

ROTARY CABLE CUTTERS

ROTO-SPLIT® CUTTERS

The RS-101A-WW and MCCUT-WW will become your everyday cutters for MC Cable. They feature a thumb screw to clamp and release the cable. You'll never do another MC Cable job without it. Proudly made in the USA.

ROTO-SPLIT® - RS-101A-WW

- Cuts or strips any armored cable from AWG 14/2 to 10/4, including AC, MC, BX, & HCF
- Cuts 3/8" trade size Flex
- Stores up to 6 extra blades in handle knob
- Durable die cast epoxy-enameled body

MODEL #	MATERIAL #	UPC	DESCRIPTION	MASTER PACK QTY.
RS-101A-WW	66978140	723875021016	Super Roto-Split®, Wounded Warrior	2
MCCUT-WW	66979340	032886911071	BX MC Rotary Cutter w/Lever	2



The RS-101AC-WW features a clamping system that covers the complete cable size range without using a thumb screw. The self-tightening blade system prevents you from damaging the cable. Proudly made in the USA.

ROTO-SPLIT® - RS-101AC-WW

- Automatically adjusts the clamping pin to the correct diameter
- Safely cut any type of armored cable by automatically adjusting to the cable diameter
- Self-tightening blade system and ergonomic crank handle with offset for maximum hand clearance
- Stores up to 6 extra blades in handle knob
- Depth of cut adjustment for standard MC cable and smaller diameter MC cable

MODEL #	MATERIAL #	UPC	DESCRIPTION	MASTER PACK QTY.
RS-101AC-WW	66978440	723875061012	Automatic Roto-Split®, Wounded Warrior	2



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

ROTARY CABLE CUTTERS

ROTO-SPLIT® CUTTERS

The RF-120A-WW provides clean cuts and does not require adjustments after the initial setting. Cutting in tight quarters is easy and fast. The self-tightening blade system prevents you from damaging the cable. The RF-120A-WW includes a blade storage cartridge in the knob with room for up to 6 spare blades. Proudly made in the USA.

ROTO-FLEX® - RF-120A-WW

- Cuts 1/2" to 3/4" flex
- Strips large AC, BX, MC cables ranging from AWG 2/3, 3/4, and 4/3
- Blade storage cartridge in knob with storage for 6 blades
- Requires no adjustment after initial setting - quick clamp lever does it all
- Die cast epoxy-enamel body

MODEL #	MATERIAL #	UPC	DESCRIPTION	MASTER PACK QTY.
RF-120A-WW	66978740	723875001209	RF-120A-WW 1/2" - 3/4" Roto-Flex™ Cutter	1



The RF-170-WW cuts up to 1-1/2" flex or armored cable in seconds leaving a clean end. It makes cutting BX and Greenfield conduit easy and precise. The self-tightening blade system prevents you from damaging the cable. The RF-170-WW includes a blade storage cartridge in the knob with room for up to 6 spare blades. Proudly made in the USA.

ROTO-FLEX® - RF-170-WW

- Cuts 1/2" to 1-1/2" flex
- Equipped with B-107 blade for aluminum
- Includes ergonomic handle with blade storage
- B-102 blade can be used with steel casing

MODEL #	MATERIAL #	UPC	DESCRIPTION	MASTER PACK QTY.
RF-170-WW	66979040	723875001704	RF-170-WW Giant Roto-Flex™ Cutter	1



1-855-798-6657 | SOUTHWIRE.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



MERCHANDISING OPTIONS

MERCHANDISING OPTIONS

WINDOW CLING

10" x 6.5"
MATERIAL #: 67036640



BADGE STICKER

MATERIAL #: 67036040



FLOOR DECAL

24" x 15"
MATERIAL #: 67036340



PLIER STICKER

MATERIAL #: 67035740



Available to order at marketingportal.southwire.com.

1-855-798-6657 | SOUTHWIRE.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & TMTrademark of Southwire Company, LLC.

MOBILE RACK



**MOBILE RACK
WINGS & HEADER**
STOCK #: 67033340

MOBILE RACK ONLY
STOCK #: 99900300

MODEL #	STOCK #	UPC	DESCRIPTIONS	MASTER PACK QTY.
SCP9TPCD-WW	67038040	032886997532	9" Side Cutting Plier, Fish Tape Puller, Crimper, Dip Grip, Wounded Warrior	6
DCPA8D-WW	67038340	032886997556	8" Diagonal Cutting Pliers, Angled Head, Dip Grip, Wounded Warrior	6
TCC9D-WW	67038640	032886997570	9" Terminal Crimper & Cutter, Dip Grip, Wounded Warrior	3
CCP9D-WW	67038940	032886997563	9" Cable Cutter, High-Leverage, Dip Grip, Wounded Warrior	6
S1020SOL-WW	67039240	032886997594	10-20 AWG SOL & 12-22 AWG STR Compact Wire Stripper, Wounded Warrior	5
S1018SOL-WW	67039540	032886997600	10-18 AWG SOL & 12-20 AWG STR Ergonomic Wire Stripper, Wounded Warrior	5
SNM1214HH-WW	67039840	032886718656	12/2 & 14/2 Romex™ Brand Box Jaw Wire Stripper, Wounded Warrior	5
RS-101A-WW	66978140	723875021016	Super Roto-Split®, Wounded Warrior	2
RS-101AC-WW	66978440	723875061012	Automatic Roto-Split®, Wounded Warrior	2
RF-120A-WW	66978740	723875001209	1/2" to 3/4" Roto-Flex™ Cutter, Wounded Warrior	1
RF-170-WW	66979040	723875001704	Giant Roto-Flex™ Cutter, Wounded Warrior	1
MCCUT-WW	66979340	032886911071	BX MC Rotary Cutter with Lever, Wounded Warrior	2
2547SWUSA1	---	029892052034	12/3 SJTW Lighted End 25'	12
2548SWUSA1	---	029892051587	12/3 SJTW Lighted End 50'	6
2549SWUSA1	---	029892051570	12/3 SJTW Lighted End 100'	4
MERCHANDISING OPTIONS				
MODEL #	STOCK #	DESCRIPTIONS		MASTER PACK QTY.
---	67033340	Header & Wings For Mobile Rack, WW		1
---	99900300	Display, Rolling Mobile Rack Black		1
---	64297980	Reorder Tags 50 per Ea.		1

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

PLAN-O-GRAM



MODEL #	STOCK #	UPC #	DESCRIPTIONS	MASTER PACK QTY.
SCP9TPCD-WW	67038040	032886997532	9" Side Cutting Plier, Fish Tape Puller, Crimper, Dip Grip, Wounded Warrior	6
DCPA8D-WW	67038340	032886997556	8" Diagonal Cutting Pliers, Angled Head, Dip Grip, Wounded Warrior	6
TCC9D-WW	67038640	032886997570	9" Terminal Crimper & Cutter, Dip Grip, Wounded Warrior	3
CCP9D-WW	67038940	032886997563	9" Cable Cutter, High-Leverage, Dip Grip, Wounded Warrior	6
S1020SOL-WW	67039240	032886997594	10-20 AWG SOL & 12-22 AWG STR Compact Wire Stripper, Wounded Warrior	5
S1018SOL-WW	67039540	032886997600	10-18 AWG SOL & 12-20 AWG STR Ergonomic Wire Stripper, Wounded Warrior	5
SNM1214HH-WW	67039840	032886718656	12/2 & 14/2 Romex™ Brand Box Jaw Wire Stripper, Wounded Warrior	5
RS-101A-WW	66978140	723875021016	Super Roto-Split®, Wounded Warrior	2
RS-101AC-WW	66978440	723875061012	Automatic Roto-Split®, Wounded Warrior	2
RF-120A-WW	66978740	723875001209	1/2" to 3/4" Roto-Flex™ Cutter, Wounded Warrior	1
RF-170-WW	66979040	723875001704	Giant Roto-Flex™ Cutter, Wounded Warrior	1
MCCUT-WW	66979340	032886911071	BX MC Rotary Cutter with Lever, Wounded Warrior	2
2547SWUSA1	---	029892052034	12/3 SJTW Lighted End 25'	12
2548SWUSA1	---	029892051587	12/3 SJTW Lighted End 50'	6
2549SWUSA1	---	029892051570	12/3 SJTW Lighted End 100'	4

MERCHANDISING OPTIONS

MODEL #	STOCK #	DESCRIPTIONS	MASTER PACK QTY.
---	67022840	Slat Wall Skin, WW Blue 4' x 6'	1
---	67021940	Header, Wounded Warrior Blue 4'	1
---	67023140	Slat Wall Skin, WW Black 4' x 6'	1
---	67022240	Header, Wounded Warrior Black 4'	1
---	64297980	Reorder Tags 50 per Ea.	1
---	64299880	Slat Wall Hook 1 per Ea.	1

1-855-798-6657 | SOUTHWIRE.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.

PLAN-O-GRAM



MODEL #	STOCK #	UPC	DESCRIPTIONS	MASTER PACK QTY.
SCP9TPCD-WW	67038040	032886699405	9" Side Cutting Plier, Fish Tape Puller, Crimper, Dip Grip, Wounded Warrior	6
DCPA8D-WW	67038340	032886997556	8" Diagonal Cutting Pliers, Angled Head, Dip Grip, Wounded Warrior	6
TCC9D-WW	67038640	032886997570	9" Terminal Crimper & Cutter, Dip Grip, Wounded Warrior	3
CCP9D-WW	67038940	032886997563	9" Cable Cutter, High-Leverage, Dip Grip, Wounded Warrior	6
S1020SOL-WW	67039240	032886997594	10-20 AWG SOL & 12-22 AWG STR Compact Wire Stripper, Wounded Warrior	5
S1018SOL-WW	67039540	032886997600	10-18 AWG SOL & 12-20 AWG STR Ergonomic Wire Stripper, Wounded Warrior	5
SNM1214HH-WW	67039840	032886718656	12/2 & 14/2 Romex™ Brand Box Jaw Wire Stripper, Wounded Warrior	5
RS-101A-WW	66978140	723875021016	Super Roto-Split®, Wounded Warrior	2

MERCHANDISING OPTIONS

MODEL #	STOCK #	DESCRIPTIONS	MASTER PACK QTY.
---	67022840	Slat Wall Skin, WW Blue 4' x 6'	1
---	67021940	Header, Wounded Warrior Blue 4'	1

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**





Southwire®

SPECIAL EDITION PRODUCT CATALOG

get social with us:



[/SOUTHWIRETOOLS](#)




[/SOUTHWIRE-COMPANY](#)



[@SOUTHWIRETOOLS](#)



[@SOUTHWIRE](#)

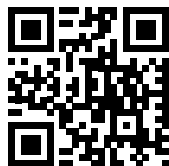

SCAN TO LEARN MORE

WWW.SOUTHWIRE.COM | 1-855-SWTOOLS

All Trademarks or Registered Trademarks (TM/®) are owned or licensed by Southwire Company. Any other TM/®- Trademark or Registered Trademark of Southwire Company.