



PRODUCT CATALOG



IllWoods®





ABOUT YELLOW JACKET®

Yellow Jacket® products are designed for a lifetime of rugged, reliable performance on the jobsite or in the workshop. We build excellent standard and added application-specific features into each item to make your job easier and safer.





TABLE OF CONTENTS

| | |
|----------------------|----|
| Power Strips | 4 |
| Power Blocks..... | 6 |
| Surge Strips..... | 9 |
| Extension Cords..... | 10 |

POWER STRIPS



6-OUTLET METAL POWER STRIP

- Metal Housing
- Overload protection
- Safety covers
- Cord clip plug
- Mountable


| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|----------------------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 5139N | 078693051395 | 6-Outlet (4+2) Metal Power Block | Yellow | 6 | 0 | 0 | 6 | 0 | 15A 120VAC 60Hz 1800W | 4 |



9-OUTLET 3' LONG METAL POWER STRIP

- Heavy duty all metal housing
- Mountable - brackets included
- Overload protection
- High visibility yellow cord
- Cord clip plug
- Lighted switch
- Snap in/snap out mounting

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|----------------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 5153 | 078693051531 | 9-Outlet Metal Power Strip | Yellow | 9 | 0 | 0 | 5 | 0 | 15A 120VAC 60Hz 1800W | 6 |

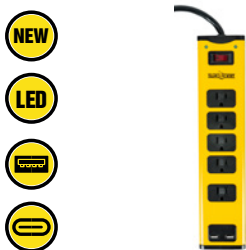

5-OUTLET MAGNET USB POWER STRIP 5FT CORD

- 5 Grounded outlets
- 2 USB-A 2.4 Amps
- 2 Rare Earth magnets (N38) creates a strong hold
- Low profile plug
- 5 foot SJT cord

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|-------------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 41275 | 078693412745 | 5 Outlet Magnetic Strip | Yellow | 5 | 2 USB-A | 2.4A | 5 | 0 | 15A 125VAC 60Hz 1875W | 6 |

POWER STRIPS



6-OUTLET METAL POWER STRIP

- All metal housing
- Integrated cord wrap
- Overload protection
- Includes plug clip
- Lighted switch
- Mountable

| Item Number | UPC | Item Description | Color | # of Outlets | Cord Length (in feet) | Electrical Ratings | # items in Master Pack |
|-------------|--------------|----------------------------|--------|--------------|-----------------------|-----------------------|------------------------|
| 4658 | 078693046582 | 6-Outlet Metal Power Strip | Yellow | 6 | 10 | 15A 120VAC 60Hz 1800W | 6 |

POWER BLOCKS



8-OUTLET POWER BLOCK

- All metal housing
- Integrated cord wrap
- Overload protection
- Includes plug clip
- Lighted switch
- Mountable

| Item Number | UPC | Item Description | Color | # of Outlets | Cord Length (in feet) | Electrical Ratings | # items in Master Pack |
|-------------|--------------|----------------------------------|--------|--------------|-----------------------|-----------------------|------------------------|
| 4655 | 029892046552 | 8-Outlet (5+3) Metal Power Block | Yellow | 8 | 6 | 15A 120VAC 60Hz 1800W | 6 |



4-OUTLET METAL POWER BLOCK

- Heavy duty all metal housing
- High visibility yellow cord
- Overload protection
- Mountable
- Cord clip plug
- Lighted switch

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|----------------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 2177N | 078693021770 | 4-Outlet Metal Power Block | Yellow | 4 | 0 | 0 | 4 | 0 | 15A 125VAC 60Hz 1875W | 6 |



8-OUTLET USB POWER BLOCK

- 2.4A USB
- Metal housing
- Integrated cord wrap
- Plug cord clip
- 2 USB Type-A ports

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|--------------------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 5148 | 078693051487 | 8-Outlet (4+2) USB Power Block | Yellow | 8 | 2 USB-A | 2.4A | 6 | 0 | 15A 120VAC 60Hz 1800W | 4 |

POWER BLOCKS



6-OUTLET INDOOR/OUTDOOR POWER BLOCK ADAPTER

- Unique 6-outlet design
- Power on LED indicator
- Protects against overloads
- Integrated circuit breaker
- Built-in cord hook to prevent accidental disconnects
- Heavy-duty impact resistant molded construction
- Outdoor rated
- Rotating weather/debris covers

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|---------------------------------------------|--------|--------------|-----------|----------------------------|-----------------------|------------------------|
| 41046 | 078693410468 | 6-Outlet Indoor/Outdoor Power Block Adapter | Yellow | 6 | 0 | 0 | 15A 125VAC 60Hz 1875W | 4 |



5-OUTLET POWER SQUID

- Flexible outlet options
- Made of high impact plastic
- Accommodates for bulky adapter plugs
- Overload protection
- Lighted switch

| Item Number | UPC | Item Description | Color | # of Outlets | Cord Length (in feet) | Electrical Ratings | # items in Master Pack |
|-------------|--------------|----------------------|-------|--------------|-----------------------|-----------------------|------------------------|
| 4921 | 029892049218 | 5-Outlet Power Squid | Black | 5 | 4 | 15A 120VAC 60Hz 1800W | 6 |



5-OUTLET OUTDOOR ADAPTER

- Integrated circuit breaker
- Power on LED indicator
- Built-in cord hook to prevent accidental disconnects
- Heavy-duty impact resistant molded construction
- Rotating weather/debris covers
- 110 degree outlet spacing fits larger plugs
- Protects against overloads

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|--------------------------|--------|--------------|-----------|----------------------------|-----------------------|------------------------|
| 41045 | 078693410451 | 5-Outlet Outdoor Adapter | Yellow | 5 | 0 | 0 | 15A 125VAC 60Hz 1875W | 6 |

POWER BLOCKS



5-OUTLET OUTDOOR ADAPTER

- 5-Outlet Power Adapter
- 14/3 SJTW 30 Foot -50 Degree Celcius Rated Cord
- Adapter has impact resistant body, cord hook, overload protection, power on indicator
- Cord is weather resistant, with a built-in cord strain relieft, hi-visibility jacket
- 50 Degree Celcius Rated Cord
- Value pack

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|---------------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 41245 | 078693412456 | Indoor/ Outdoor Power Set | Yellow | 6 | 0 | 0 | 30 | 0 | 15A 125VAC 60Hz 1875W | 6 |



8-OUTLET POWER WHEEL, 2 USB, 6FT CORD

- Unique spread outlet design
- 2 USB-A ports at 2.4 Amps
- Integrated cord hook
- 6 foot cord
- Overload protection

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|-----------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 41293 | 078693412936 | 8 Outlets Power Wheel | Yellow | 6 | 2 | 2.4A | 6 | 0 | 15A 125VAC 60Hz 1875W | 6 |

SURGE STRIPS



6-OUTLET METAL SURGE STRIP

- Surge protector
- Heavy duty all metal housing
- Overload protection
- Safety covers
- Cord clip plug
- Lighted switch
- Mountable

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|--------------------------------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 5138N | 078693051388 | 6-Outlet (4+2) 1440J Metal Surge Protector | Yellow | 6 | 0 | 0 | 15 | 1440 Joules | 15A 120VAC 60Hz 1800W | 4 |



12-OUTLET 4' LONG 510J METAL SURGE STRIP

- Heavy duty all metal housing
- Overload protection
- Mountable - brackets included
- High visibility yellow cord
- Cord clip plug
- Lighted switch
- Snap in/snap out mounting

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|----------------------------------|--------|--------------|-----------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 5154 | 078693051548 | 12-Outlet 510J Metal Surge Strip | Yellow | 12 | 0 | 0 | 6 | 510 Joules | 15A 120VAC 60Hz 1800W | 6 |



LED LIGHT AND USB WITH 10-OUTLET SURGE STRIP WITH LED

- Unique spread outlet design
- 1 USB-A ports at 2.4 Amps
- Integrated cord hook
- 4 foot cord
- Overload protection
- 2 LED lights at 1000 Lumens each
- 1350 Joules of surge protection

| Item Number | UPC | Item Description | Color | # of Outlets | USB Ports | Amps | Cord Length (in feet) | Joules of Surge Protection | Electrical Ratings | # items in Master Pack |
|-------------|--------------|------------------------------|--------|--------------|--------------------|------|-----------------------|----------------------------|-----------------------|------------------------|
| 41273 | 078693412738 | 10 Outlet Workshop Surge Bar | Yellow | 10 | 1 USB-A 1 USB-C | 2.4A | 4 | 1350 Joules | 15A 125VAC 60Hz 1875W | 4 |

EXTENSION CORDS



EXTENSION CORDS WITH LIGHTED ENDS

- Temperature rating of -58°F to 140°F (-50°C to 60°C)
- 125 Voltage Rating
- Abrasion, chemical and oil resistant
- Common Applications: Table Saw, Electric Drill, Work Light

| Part # | Gauge/Conductors | Jacket Type | Length (ft) | Length (m) | Cord Color | Amps | Case Pack Quantity |
|--------|------------------|--------------|-------------|------------|------------|------|--------------------|
| 2886 | 14/3 | Premium SJTW | 25' | 7.6 m | Yellow | 15 | 12 |
| 2887 | 14/3 | Premium SJTW | 50' | 15.2 m | Yellow | 15 | 6 |
| 2888 | 14/3 | Premium SJTW | 100' | 30.5 m | Yellow | 13 | 3 |
| 2883 | 12/3 | Premium SJTW | 25' | 7.6 m | Yellow | 15 | 6 |
| 2884 | 12/3 | Premium SJTW | 50' | 15.2 m | Yellow | 15 | 4 |
| 2885 | 12/3 | Premium SJTW | 100' | 30.5 m | Yellow | 15 | 2 |
| 2805 | 10/3 | Premium SJTW | 50' | 15.2 m | Yellow | 15 | 2 |
| 2806 | 10/3 | Premium SJTW | 100' | 30.5 m | Yellow | 15 | 2 |



TRITAP EXTENSION CORDS WITH LIGHTED ENDS

- Temperature rating of -58°F to 140°F (-50°C to 60°C)
- 125 Voltage Rating
- Abrasion, chemical and oil resistant
- Common Applications: Table Saw, Electric Drill, Work Light

| Part # | Gauge/Conductors | Jacket Type | Length (ft) | Length (m) | Cord Color | Amps | Case Pack Quantity |
|------------|------------------|--------------|-------------|------------|------------|------|--------------------|
| 2882 | 12/3 | Premium STW | 2' | 0.6 m | Yellow | 15 | 10 |
| 51002301** | 12/3 | Premium SJTW | 25' | 7.6 m | Yellow | 15 | 10 |
| 2827 | 12/3 | Premium SJTW | 50' | 15.2 m | Yellow | 15 | 4 |
| 2820 | 12/3 | Premium SJTW | 100' | 30.5 m | Yellow | 15 | 2 |

10 **Product packaging is advertised in Meters



MULTI-OUTLET EXTENSION CORD

- Temperature rating of -58°F to 140°F (-50°C to 60°C)
- 125 Voltage Rating
- Abrasion, chemical and oil resistant
- Common Applications: Table Saw, Electric Drill, Work Light

| Part # | Gauge/Conductors | Jacket Type | Length (ft) | Length (m) | Cord Color | Amps | Case Pack Quantity |
|--------|------------------|-------------|-------------|------------|------------|------|--------------------|
| 2830 | 12/3 | Premium STW | 25' | 7.6 m | Yellow | 15 | 2 |



LOCKING PLUG EXTENSION CORDS

- Temperature rating of -58°F to 140°F (-50°C to 60°C)
- 125 Voltage Rating
- Abrasion, chemical and oil resistant
- Common Applications: Table Saw, Electric Drill, Work Light

| Part # | Gauge/Conductors | Jacket Type | Length (ft) | Length (m) | Cord Color | Amps | Case Pack Quantity |
|--------|------------------|--------------|-------------|------------|------------|------|--------------------|
| 2734 | 14/3 | Premium SJTW | 50' | 15.2 m | Yellow | 15 | 6 |
| 2737 | 12/3 | Premium SJTW | 50' | 15.2 m | Yellow | 15 | 4 |
| 2738 | 12/3 | Premium SJTW | 100' | 30.5 m | Yellow | 15 | 2 |



EXTENSION CORDS W/ T-BLADE

- Temperature rating of -58°F to 140°F (-50°C to 60°C)
- 125 Voltage Rating
- Abrasion, chemical and oil resistant
- Common Applications: Table Saw, Electric Drill, Work Light

| Part # | Gauge/Conductors | Jacket Type | Length (ft) | Length (m) | Cord Color | Amps | Case Pack Quantity |
|--------|------------------|--------------|-------------|------------|------------|------|--------------------|
| 2991* | 10/3 | Premium SJTW | 50' | 15.2 m | Yellow | 20 | 2 |
| 2992* | 10/3 | Premium SJTW | 100' | 30.5 m | Yellow | 20 | 2 |

*NEMA 5-20 P/R

EXTENSION CORDS



TWIST-TO-LOCK GENERATOR CORDS

- Temperature rating of -58°F to 140°F (-50°C to 60°C)
- 125 Voltage Rating
- Abrasion, chemical and oil resistant
- Common Applications: Table Saw, Electric Drill, Work Light

| Part # | Gauge/Conductors | Jacket Type | Length (ft) | Length (m) | Cord Color | Amps | Case Pack Quantity |
|--------|------------------|-------------|-------------|------------|------------|------|--------------------|
| 1381* | 10/4 | Premium STW | 25' | 7.6 m | Yellow | 20 | 2 |
| 1493^ | 10/4 | Premium STW | 25' | 7.6 m | Yellow | 30 | 2 |

* NEMA L14-20 P/R

^NEMA L14-30 P/R

**Product packaging is advertised in Meters





Rev.1, 05/24

©2024 Southwire Company, LLC. All rights reserved.
Registered Trademark & ™Trademark of Southwire Company, LLC.