

-GENESIS-
Entertainment Cable
Solutions for Every Installation



Entertainment Cable

Enabling Your Success

Genesis. Wire that Works – the first time, every time. Engineered and tested to exceed the highest quality standards, Genesis low-voltage cable is trusted by contractors worldwide to produce consistent system performance for a wide range of residential and commercial applications.

Our cable delivers a hassle-free experience – from sale to installation – that drives repeat business and gets pros in and out of jobs faster. Genesis Cable optimizes entertainment system longevity, ensures high performance and drives a greater return on investment. **Count on it.**





Hassle-Free Solutions for Every Application

Conferencing and meeting systems. Home theater audio. Cable and satellite television.



Audacious Sound Cable®

Expertly engineered with oxygen-free copper conductors and a high strand count to deliver better quality and bolder sound.




Home Theater Sound Cable

Twisted bare copper conductors moderate the effects of electromagnetic interference in this go-to audio cable solution. Designed for uncompromising performance and unparalleled value.

Your Single Source Provider

Genesis offers the most complete selection of low-voltage cable with access to products across Entertainment (A/V), Comfort (HVAC), Security, Fire & Life Safety and Networking & Communication. With product availability at **thousands of locations throughout the United States, Canada and Latin America**, you can depend on Genesis Cable for every job across residential and commercial applications. **With industry-leading programs, warranties and a dedicated Customer Service Team, Genesis has your back. Count on it.**

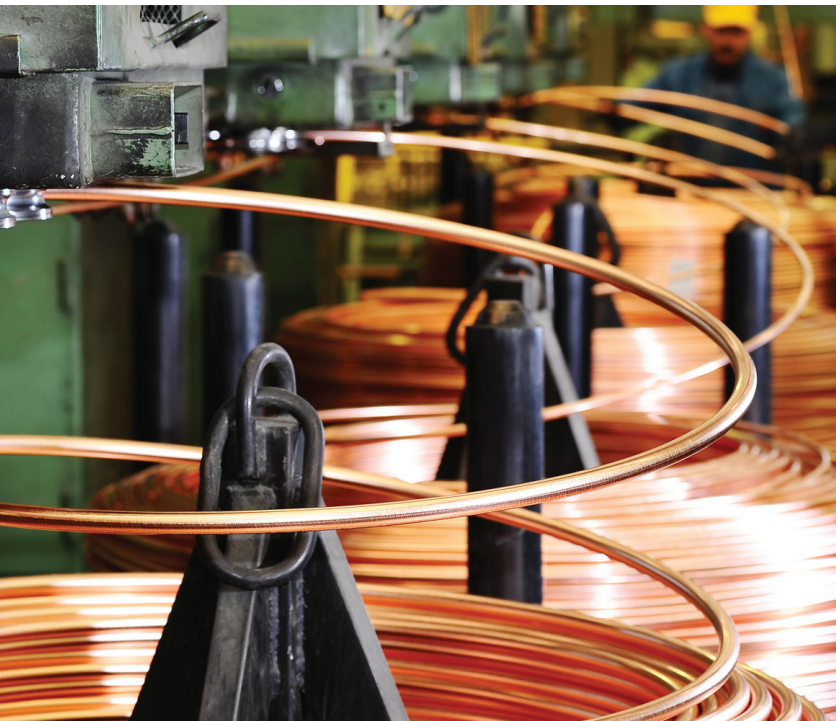

Toll-Free Customer Support

We deliver confidence by ensuring prompt response and resolution when and where you need it. When you work with Genesis, you work with the best.

3-for-1 Warranty

At Genesis, we insure protection for you and your customers. If any cable fails to perform to spec, we'll replace it – three units to one.



In Stock, Readily Available

Genesis keeps your business running on schedule, with product availability at thousands of locations across the United States, Canada and Latin America.

Audacious Sound Cable®



AWG	Number of Conductors	Stranding	Shield	DC Resistance (Ohms/1000')	Nominal Capacitance (pF/ft.)	Nominal Outer Diameter (Inches)	Average Weight (Pounds/1000')	Part Number
Riser Rated (CMR/FT4 Sunlight Resistant Listed)								
16	2	65 Strand	Unshielded	4.19	39.8	0.250	36.4	5473
16	4	65 Strand	Unshielded	4.19	39.8	0.294	57.4	5474
14	2	105 Strand	Unshielded	2.62	44.9	0.306	49.3	5475
14	4	105 Strand	Unshielded	2.62	44.9	0.347	84.1	5476
12	2	105 Strand	Unshielded	1.65	49.3	0.340	34.0	5477
Direct Burial Rated (CM/CL3, Direct Burial, Sunlight Resistant Listed)								
16	2	65 Strand	Unshielded	4.19	35.2	0.274	45.3	5283
16	4	65 Strand	Unshielded	4.19	35.2	0.350	76.3	5284
14	2	105 Strand	Unshielded	2.62	40.0	0.320	61.1	5285
14	4	105 Strand	Unshielded	2.62	40.0	0.365	104.5	5286

Home Theater Sound



AWG	Number of Conductors	Stranding	Shield	DC Resistance (Ohms/1000')	Nominal Capacitance (pF/ft.)	Nominal Outer Diameter (Inches)	Average Weight (Pounds/1000')	Part Number
Riser Rated (CMR/CL3R/FT4 Sunlight Resistant Listed)								
16	2	26 Strand	Unshielded	4.19	22.5	0.180	22.7	5250
16	4	26 Strand	Unshielded	4.19	22.5	0.210	42.7	5251
14	2	41 Strand	Unshielded	2.62	24.6	0.224	35.6	5252
14	4	41 Strand	Unshielded	2.62	24.6	0.260	65.7	5253
12	2	65 Strand	Unshielded	1.65	26.4	0.264	52.7	5254

CATV Coaxial Video



AWG / Style	Shield	Characteristic Impedance (Ohms)	Velocity of Propagation (%)	DC Resistance (Ohms/1000')	Nominal Capacitance (pF/ft.)	Nominal Outer Diameter (Inches)	Average Weight (Pounds/1000')	Part Number
Riser Rated (CATVR/FT4 Sunlight Resistant Listed)								
18 AWG CCS RG6	Quad-Shield	75	81	31.10	16.5	0.293	30.0	5307
18 AWG CCS RG6	Dual-Shield	75	81	31.10	16.5	0.272	30.0	5303
General Purpose Rated (CATV Sunlight Resistant Listed)								
14 AWG CCS RG11	Dual-Shield	75	81	12.25	16.5	0.400	62.0	5018
18 AWG CCS RG6	Quad-Shield	75	81	31.10	16.5	0.298	33.0	5007
18 AWG CCS RG6	Dual-Shield	75	81	31.10	16.5	0.272	29.0	5003
18 AWG BC RG6	Quad-Shield	75	81	6.52	16.5	0.293	35.0	5027
18 AWG BC RG6	Dual-Shield	75	81	6.52	16.5	0.272	30.0	5304

Genesis Cable
7701 95th Street
Pleasant Prairie, WI 53158
Office: 800.222.0060
www.genescable.com

© 2024 Genesis Cable

-GENESIS-